

# Air terminal base, Stamped adjustable, Metric Thread



## CERTIFICATIONS



## FEATURES

For use on flat, vertical or sloping surface

Air terminal support tab is field adjustable, eliminating the need for swivel adaptor

Available pre-configured for vertical applications

Install with adhesive or screw down fixing

Positive single bolt tension for multi-directional cable clamping

Tested in accordance with IEC 62561-1


## SPECIFICATIONS

Table 1/2

Catalog Number	Thread Size (TS)	Type	Material	Hole Size (HS)	Depth (D)	Height (H)
LPA302M16A	M16	Flat	Aluminum	7.14 mm	88.9mm	42.1 mm

Table 2/2		
Catalog Number	Width (W)	Conductor Size
LPA302M16A	101.6 mm	8 mm Solid - 10 mm Solid, 120 mm <sup>2</sup> Stranded

### DIAGRAMS

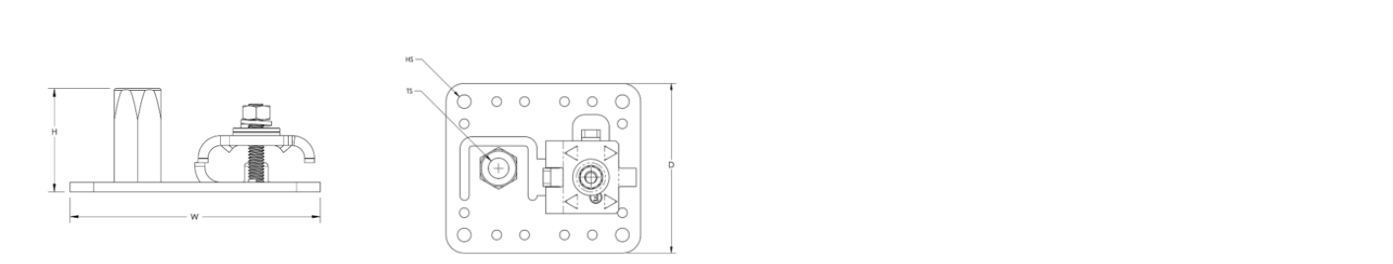

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE