

Data Equipment Protector



FEATURES

Models to cover RS-232, RS-423, RS-422 and RS-485 protocols


Designed to provide both line to signal-ground and signal-ground to protective-earth protection

Plug-in protection is simple to install

SPECIFICATIONS

Catalog Number	DEPRS23299D	DEPRS42299D	DEPRS2322525D
Nominal Discharge Current (In)	0.3kA 8/20 μ s	0.4kA 8/20 μ s	0.3kA 8/20 μ s
Max Continuous Operating Voltage (Uc)	15 VDC	9 VDC	15 VDC
Capacitance	30 pF Max	30 pF Max	30 pF Max
Protection Modes	All pins to ground	All pins to ground	All pins to ground
Connection Type	DB9, Male/Female	DB9, Male/Female	DB25, Male/Female
Depth (D)	61mm	61mm	61mm
Height (H)	16.6 mm	16.6 mm	16.6 mm
Width (W)	30.5 mm	30.5 mm	53.5 mm
Unit Weight	0.05 kg	0.05 kg	0.08 kg

DIAGRAMS

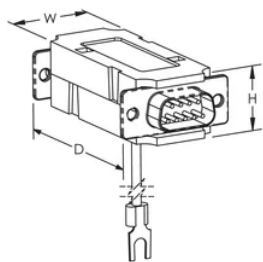

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE