

Flush mount conductor clamp



FEATURES

Conductor clamps used for solid round conductor

Type of structure mounted on concrete, brick, metal plate, etc

Corrosion resistant

Stainless steel slotted hex head & Flat Head Wood screw (with plastic dowel) included for fixing clamp

Tested in accordance with IEC 62561-4

SPECIFICATIONS


Table 1/2

Catalog Number	Conductor Size	A	B	C	Material	Torque (TQ)
LPS800810A	8 mm Solid - 10 mm Solid	20 mm	45 mm	13 mm	Carbon Steel	16.9 N·m

Table 2/2

Catalog Number	Unit Weight
LPS800810A	0.065 kg

DIAGRAMS

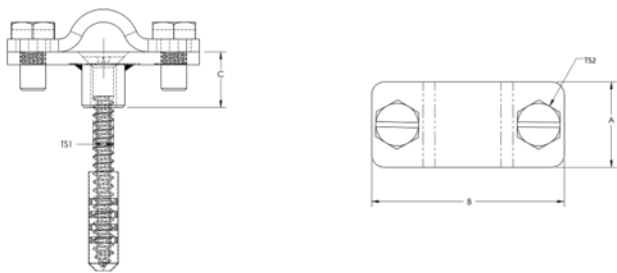

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE