

# Pipe Collar



## FEATURES

Clamp for bonding of pipes and exhaust stacks to the lightning protection system

Secures conductor to horizontal or vertical round mounting points


## SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Material	Conductor Size	Outer Diameter (OD)	Width (W)	Unit Weight
SPC5080S	107000	Stainless Steel 18-8 (EN 1.4305)	6 mm Solid - 11 mm Solid	50 - 80 mm	40 mm	0.15 kg
SPC70120S	107010	Stainless Steel 18-8 (EN 1.4305)	6 mm Solid - 11 mm Solid	70 - 120 mm	40 mm	0.17 kg
SPC5080C	107050	Copper	6 mm Solid - 11 mm Solid	50 - 80 mm	40 mm	0.17 kg
SPC70120C	107060	Copper	6 mm Solid - 11 mm Solid	70 - 120 mm	40 mm	0.19 kg
SPC130180S	107020	Stainless Steel 18-8 (EN 1.4305)	6 mm Solid - 11 mm Solid	130 - 180 mm	40 mm	0.21 kg
SPC130180C	107070	Copper	6 mm Solid - 11 mm Solid	130 - 180 mm	40 mm	0.24 kg

## DIAGRAMS

---

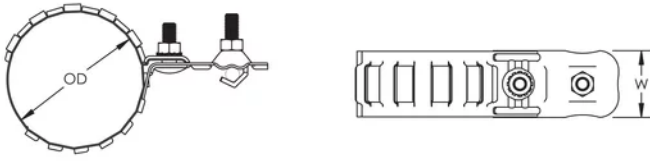

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**