

Standing beam clamp for solid round conductor



FEATURES

Stainless steel clamp to metal objects such as rectangular, rounded, I-beams, angle irons and channel irons

Comes with one hole cable straps to secure conductor

For use with solid round conductor

Tested in accordance with IEC 62561-4

SPECIFICATIONS


Table 1/2

Catalog Number	Height (H)	Width (W)	Depth (D)	Thread Size (TS)	Clamping Range	Material
LPS810A	30 mm	26 mm	34mm	M6	2 - 22 mm	Stainless Steel 304 (EN 1.4301)
LPS808A	30 mm	26 mm	34mm	M6	2 - 22 mm	Stainless Steel 304 (EN 1.4301)

Table 2/2

Catalog Number	Flange Thickness (FT)	Unit Weight
LPS810A	2 - 22 mm	0.085 kg
LPS808A	2 - 22 mm	0.085 kg

DIAGRAMS

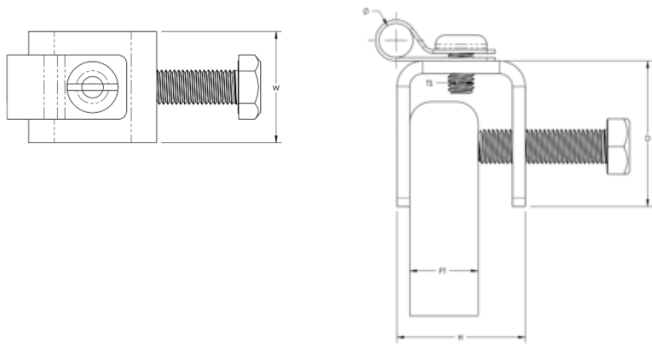

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE