


# Mounting Plates For Power Distribution, MSMPN

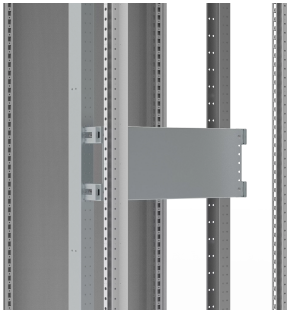

The mounting plate, MSMPN, for fix and modular systems, can be easily machined and have components mounted on it before fixed within the relevant compartment.

## FEATURES

Description: Mounting plate for installation of breakers. Suitable for left and right hand connections.

Material: 1.5 mm galvanized steel.

Pack quantity: 1 piece with mounting material.

Mounting requirements: To be assembled on the modular system frame with MSMPA01 or MSMPF01.

## SPECIFICATIONS

**Finish:** Plated

**Material:** Steel

Table 1/1

Catalog Number	Height	Width	Type	Fits Enclosure Size	Panel Size	Enclosure Material
MSMPN1008H	10mm	800mm	Horizontal Opening	100 x 800mm	96 x 670mm	Mild Steel
MSMPN0506	50mm	600mm	Plain	50 x 600mm	496 x 470mm	Mild Steel
MSMPN0508	50mm	800mm	Plain	50 x 800mm	496 x 670mm	Mild Steel
MSMPN1006	100mm	600mm	Plain	100 x 600mm	96 x 470mm	Mild Steel
MSMPN1006H	100mm	600mm	Horizontal Opening	100 x 600mm	96 x 470mm	Mild Steel
MSMPN1008	100mm	800mm	Plain	100 x 800mm	96 x 670mm	Mild Steel
MSMPN1506	150mm	600mm	Plain	150 x 600mm	146 x 470mm	Mild Steel
MSMPN1506V	150mm	600mm	Vertical Opening	150 x 600mm	146 x 470mm	Mild Steel
MSMPN1508	150mm	800mm	Plain	150 x 800mm	146 x 670mm	Mild Steel
MSMPN1508V	150mm	800mm	Vertical Opening	150 x 800mm	146 x 670mm	Mild Steel
MSMPN2006	200mm	600mm	Plain	200 x 600mm	196 x 470mm	Mild Steel
MSMPN2006V	200mm	800mm	Vertical Opening	200 x 600mm	196 x 470mm	Mild Steel
MSMPN2008	250mm	600mm	Plain	200 x 800mm	196 x 670mm	Mild Steel
MSMPN2008V	200mm	800mm	Vertical Opening	200 x 800mm	196 x 670mm	Mild Steel
MSMPN2506	250mm	600mm	Plain	250 x 600mm	246 x 470mm	Mild Steel
MSMPN2506V	250mm	600mm	Vertical Opening	250 x 600mm	246 x 470mm	Mild Steel
MSMPN2508	250mm	800mm	Plain	250 x 800mm	246 x 670mm	Mild Steel

Catalog Number	Height	Width	Type	Fits EnclosureSize	Panel Size	EnclosureMaterial
MSMPN2508V	250mm	800mm	Vertical Opening	250 x 800mm	246 x 670mm	Mild Steel
MSMPN3006	300mm	600mm	Plain	300 x 600mm	296 x 470mm	Mild Steel
MSMPN3006V	300mm	600mm	Vertical Opening	300 x 600mm	296 x 470mm	Mild Steel
MSMPN3008	300mm	800mm	Plain	300 x 800mm	296 x 670mm	Mild Steel
MSMPN3008V	300mm	800mm	Vertical Opening	300 x 800mm	296 x 670mm	Mild Steel
MSMPN4006	400mm	600mm	Plain	400 x 600mm	396 x 470mm	Mild Steel
MSMPN4006V	400mm	600mm	Vertical Opening	400 x 600mm	396 x 470mm	Mild Steel
MSMPN4008	400mm	800mm	Plain	400 x 800mm	396 x 670mm	Mild Steel
MSMPN4008V	400mm	800mm	Vertical Opening	400 x 800mm	396 x 670mm	Mild Steel
MSMPN4506	450mm	600mm	Plain	450 x 600mm	446 x 470mm	Mild Steel
MSMPN4506V	450mm	600mm	Vertical Opening	450 x 600mm	446 x 470mm	Mild Steel
MSMPN4508	450mm	800mm	Plain	450 x 800mm	446 x 670mm	Mild Steel
MSMPN4508V	450mm	800mm	Vertical Opening	450 x 800mm	446 x 670mm	Mild Steel
MSMPN5006	500mm	600mm	Plain	500 x 600mm	496 x 470mm	Mild Steel
MSMPN5008	500mm	800mm	Plain	500 x 800mm	496 x 670mm	Mild Steel
MSMPN6006	600mm	600mm	Plain	600 x 600mm	596 x 470mm	Mild Steel
MSMPN6006V	600mm	600mm	Vertical Opening	600 x 600mm	596 x 470mm	Mild Steel
MSMPN6008	600mm	800mm	Plain	600 x 800mm	596 x 670mm	Mild Steel
MSMPN6008V	600mm	1000mm	Vertical Opening	600 x 800mm	596 x 670mm	Mild Steel
MSMPN6010	600mm	1000mm	Plain	600 x 1000mm	596 x 870mm	Mild Steel

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**