

# ELICP Internal Plastic nVent LENTON Form Saver Plug for A2 Couplers



## FEATURES

Designed for use with the A2 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

O-ring provides hydraulic seal

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Material:** High Density Polyethylene (HDPE)

Table 1/2

| Catalog Number | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Width 1 (W1) | Width 2 (W2) | A     |
|----------------|--------------------|----------------|--------------------|--------------|--------------|-------|
| ELICP20        | 20 mm              | #6             | 20M                | 57 mm        | 13 mm        | 10 mm |
| ELICP22        | 22 mm              | #7             |                    | 60 mm        | 13 mm        | 13 mm |
| ELICP25        | 25 mm              | #8             | 25M                | 64 mm        | 13 mm        | 13 mm |
| ELICP28        | 28 mm              | #9             | 30M                | 67 mm        | 13 mm        | 13 mm |

| CatalogNumber | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Width 1 (W1) | Width 2 (W2) | A     |
|---------------|--------------------|----------------|--------------------|--------------|--------------|-------|
| ELICP32       | 32 mm              | #10            |                    | 70 mm        | 13 mm        | 13 mm |
| ELICP36       | 36 mm              | #11            | 35M                | 75 mm        | 13 mm        | 13 mm |
| ELICP43       | 43 mm              | #14            | 45M                | 83 mm        | 16 mm        | 13 mm |
| ELICP57       | 57 mm              | #18            | 55M                | 102 mm       | 25 mm        | 13 mm |


Table 2/2

| Catalog Number | Height (H) | Color  |
|----------------|------------|--------|
| ELICP20        | 11 mm      | Yellow |
| ELICP22        | 11 mm      | Blue   |
| ELICP25        | 11 mm      | Red    |
| ELICP28        | 11 mm      | Black  |
| ELICP32        | 11 mm      | Yellow |
| ELICP36        | 11 mm      | Blue   |
| ELICP43        | 11 mm      | Red    |
| ELICP57        | 11 mm      | Blue   |

## ADDITIONAL PRODUCT DETAILS

ELICP36 can also be used with P8/P9 position couplers for form saving applications (sizes 20, 22, 25 only).

DIAGRAMS

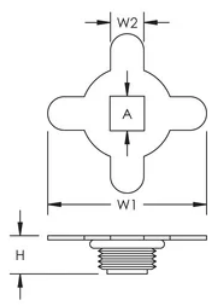

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE