 


# PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, Worldwide Design



## FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Material:** High Density Polyethylene (HDPE);Steel


**Design Version:** Worldwide (Globally Available Materials)

Table 1/1

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL12PFFN	12 mm	#4	10M	65 mm	17 mm	Red
EL16PFFN	16 mm	#5	15M	65 mm	20 mm	Black
EL20PFFN	20 mm	#6	20M	75 mm	20 mm	Yellow
EL22PFFN	22 mm	#7		95 mm	20 mm	Blue

CatalogNumber	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL25PFFN	25 mm	#8	25M	95 mm	20 mm	Red
EL28PFFN	28 mm	#9	30M	95 mm	20 mm	Black
EL32PFFN	32 mm	#10		95 mm	20 mm	Yellow
EL36PFFN	36 mm	#11	35M	95 mm	20 mm	Blue
EL40PFFN	40 mm			95 mm	20 mm	Green

## DIAGRAMS

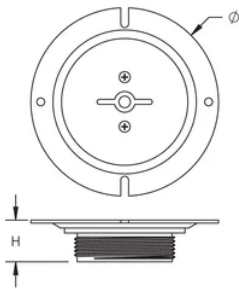

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**