


Horizontal Rail, Rear, Center, Type MZ, With Z-Rail, 40 HP

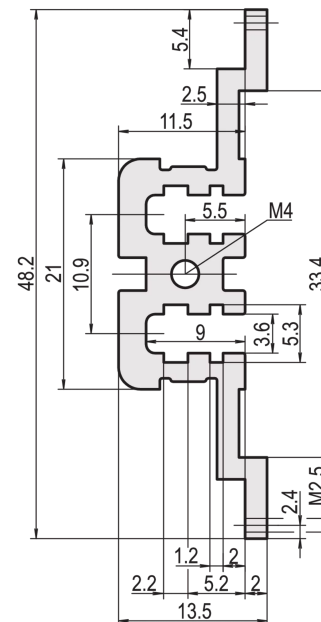



Power Utilities

CATALOG NUMBER

34561-240



Combinations of horizontal rails and side panels

	Light = L	Chandelier = C	Recess = R	Knaggl = K
Recess x R		-	+	+
Light x L		+	+	+
Knaggl x K		+	+	+
Chandelier x C		+	+	+

Legend: + = can be combined, - = combination not recommended

The horizontal rail, center, type MZ enables the use of DIN connectors in accordance with EN 60603-2.

CERTIFICATIONS



FEATURES

For directly mounting connectors complying with EN 60603 (DIN 41612)

Aluminum extrusion, anodized surface, conductive contact surface, without printed markings

PRODUCT ATTRIBUTES

Product Type: Horizontal Rail

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Type: Type MZ

Rack Width: 40 HP

Length: 208.28 mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE