


# EuropacPRO Rugged Rear Angle for Textile EMC Gasket

## Power Utilities

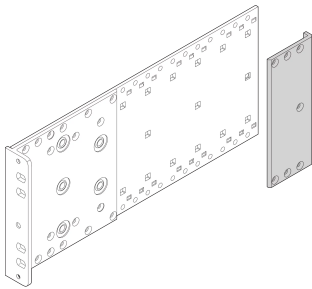

Corner profile covers the slot between the side panel and the rear panel of a subrack. Needed for a proper EMC shielding.

## CERTIFICATIONS



## FEATURES

Required for shielding of rear

Can also be used as front closure when using a depth-adjustable 19" support bracket

## SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Package Quantity	Height	Product Family	Product Type	Type
24566-197	3 U	1	132.6 mm	EuropacPRO	Cover	Rugged
24566-199	3 U	1	132.6 mm	EuropacPRO	Cover	Rugged

CatalogNumber	Rack Height	Package Quantity	Height	Product Family	Product Type	Type
24566-497	6 U	1	265.9 mm	EuropacPRO	Cover	Rugged
24566-499	6 U	1	265.9 mm	EuropacPRO	Cover	Rugged

Table 2/2

Catalog Number	Works With	Package Unit	Certifications
24566-197	Subracks	Pair	
24566-199	Subracks	Pair	RoHS
24566-497	Subracks	Pair	
24566-499	Subracks	Pair	RoHS

## ADDITIONAL PRODUCT DETAILS

Please order EMC textile gasket separately.

Corner profile cannot be used together with adapter for rear mounting.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**