


## Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

## Power Utilities

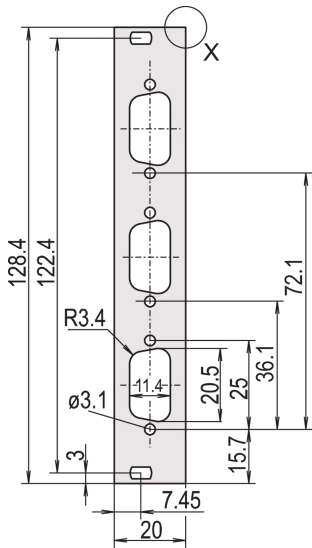

Flat front panel with cutout for D-Sub connectors.  
Shieldable for stainless steel EMC gasket.

## CERTIFICATIONS



## FEATURES

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

## SPECIFICATIONS

Table 1/3						
Catalog Number	Package Quantity	Mounting	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges

30118-348	5	Screw-on Front	Stainless Steel	Anodized	Conductive	No
30118-349	5	Screw-on Front	Stainless Steel	Anodized	Conductive	No
30118-350	5	Screw-on Front	Stainless Steel	Anodized	Conductive	No
30118-351	5	Screw-on Front	Stainless Steel	Anodized	Conductive	No
30118-352	5	Screw-on Front	Stainless Steel	Anodized	Conductive	No
30118-353	5	Screw-on Front	Stainless Steel	Anodized	Conductive	No
30118-354	5	Screw-on Front	Stainless Steel	Anodized	Conductive	No

Table 2/3						
Catalog Number	Complies With	EMC Shielding	Height	Material	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminum	Front Panel	3 U

Table 3/3			
Catalog Number	Rack Width	Type	Width

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

## ADDITIONAL PRODUCT DETAILS

---

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**