


# Horizontal Rails Threaded Insert, M2.5

## Power Utilities

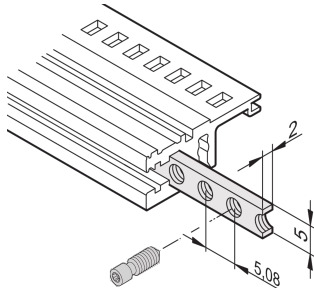

The threaded insert is a metal strip with thread M2.5 and allows the fixing of front panels.

## CERTIFICATIONS



## FEATURES

The collar screws used for fixing partial-width front panels must be 12.3 mm long

Usable for all horizontal rails

## SPECIFICATIONS

Table 1/2

| Catalog Number | Rack Width | Package Quantity | Length    | Material | Product Family                                                                          | Product Type    |
|----------------|------------|------------------|-----------|----------|-----------------------------------------------------------------------------------------|-----------------|
| 34561-328      | 28 HP      | 1                | 146.82 mm | Steel    | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO,<br>Inpac | Threaded Insert |

| CatalogNumber | Rack Width | Package Quantity | Length    | Material | Product Family                                                                          | Product Type    |
|---------------|------------|------------------|-----------|----------|-----------------------------------------------------------------------------------------|-----------------|
| 34561-363     | 84 HP      | 1                | 324.62 mm | Steel    | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO,<br>Inpac | Threaded Insert |
| 34561-342     | 42 HP      | 1                | 217.94 mm | Steel    | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO,<br>Inpac | Threaded Insert |
| 34561-384     | 84 HP      | 1                | 431.3 mm  | Steel    | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO,<br>Inpac | Threaded Insert |

Table 2/2

| Catalog Number | Works With      |
|----------------|-----------------|
| 34561-328      | Subracks, Cases |
| 34561-363      | Subracks, Cases |
| 34561-342      | Subracks, Cases |
| 34561-384      | Subracks, Cases |

## ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**