


19" Front Panel for Cable Eyes

19" front panel are for accommodating cable eyes.

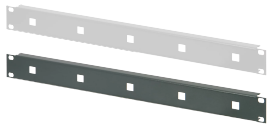

CERTIFICATIONS



FEATURES

19" front panel to accommodate cable eyes (to mount the eyes, insert and rotate them 45°)

SPECIFICATIONS

Depth:	1.5mm
Rack Width:	95HP
Accessory Type:	Front panel
Product Type:	Front Panel
Material:	Steel

Table 1/2

Catalog Number	Rack Height	Mounting	Package Quantity	Front Finish	Rear Finish	Color Code
20118-761	1U	Screw-on Front	1	Painted	Painted	RAL 7035
20118-762	1U	Screw-on Front	1	Painted	Painted	RAL 7021

Table 2/2

Catalog Number	EMC Shielding	Finish	Height	Type	Width	Quick Ship
20118-761	No	Powder Coated	43.6mm	19" Front Panel	483mm	No
20118-762	No	Powder Coated	43.6mm	19" Front Panel	483mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE