


19" Front Panel With Holes for Handles, 1 U, 3 mm, Al, Anodized, Untreated Edges

CATALOG NUMBER

30219-161

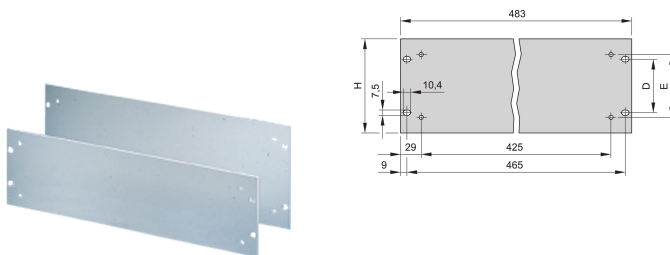

Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

CERTIFICATIONS



FEATURES

19" front panels have additional holes for mounting of handles

PRODUCT ATTRIBUTES

Rack Height: 1U

Depth (D): 3mm

Accessory Type: Front panel

Handle Type: Front Handle

Finish: Anodized

Mounting: Screw-on Front

Package Quantity: 1

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: No

EMC Shielding: No

Height (H): 43.6mm

Material: Aluminum

Product Type: Front Panel


Rack Width: 95HP

Type: 19" Front Panel

Width (W): 483mm

Net Weight: 0.16kg

DIAGRAMS

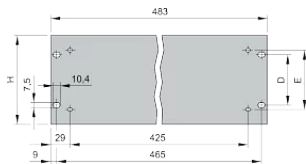

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE