


# EuropacPRO Advanced EMC 45 Top and Bottom Covers, Screwed to Side Panel, Ø 2.3mm

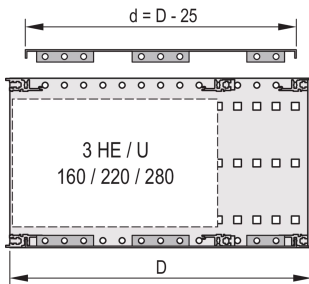

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

## CERTIFICATIONS



## FEATURES

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1, perforation diameter Ø 2.3mm, degree 50%

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Product Type:</b>	Cover Plate
<b>Product Family:</b>	EuropacPRO
<b>Finish:</b>	Passivated
<b>Type:</b>	Perforated
<b>Works With:</b>	Subracks

Table 1/1

Catalog Number	Rack Width	Depth	Package Quantity	Package Unit	Quick Ship
----------------	------------	-------	------------------	--------------	------------

24563-560	42HP	175mm	2	Pair	No
24563-556	36HP	235mm	2	Pair	No
24563-660	63HP	175mm	2	Pair	No
24563-760	84HP	175mm	2	Pair	No
24563-761	84HP	235mm	2	Pair	No
24563-762	84HP	275mm	2	Pair	No
24563-764	84HP	295mm	2	Pair	No
24563-766	84HP	415mm	2	Pair	No
24563-765	84HP	355mm	2	Pair	No
24563-555	36HP	175mm	2	Pair	No
24563-561	42HP	235mm	2	Pair	No
24563-562	42HP	275mm	2	Pair	No
24563-563	42HP	277.75mm	2	Pair	No
24563-564	42HP	295mm	2	Pair	No
24563-661	63HP	235mm	2	Pair	No
24563-662	63HP	275mm	2	Pair	No
24563-663	63HP	295mm	2	Pair	No
24563-763	84HP	277.75mm	2	Pair	No
24563-767	84HP	495mm	2	Pair	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**