


Plug-In Unit U-Profile Front Panel for XL Handle

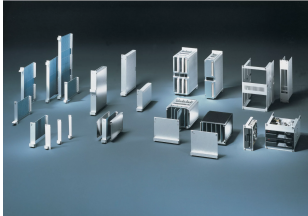

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

CERTIFICATIONS



FEATURES

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

SPECIFICATIONS

| | |
|------------------------|------------------------------|
| Material: | Aluminum |
| Finish: | Anodized; Passivated |
| Accessory Type: | Front panel |
| Product Type: | Front Panel |
| Type: | Front Panel for Handle (PIU) |
| EMC Shielding: | No (Retrofittable) |

Table 1/3

| Catalog Number | Rack Width | Package Quantity | Handle Type | Mounting | EMC Gasket Type | Front Finish |
|----------------|------------|------------------|-------------|----------------|-----------------|--------------|
| 30849-153 | 4HP | 1 | XL | Screw-on Front | Textile | Anodized |

| CatalogNumber | Rack Width | Package Quantity | Handle Type | Mounting | EMC Gasket Type | Front Finish |
|---------------|------------|------------------|-------------|----------------|-----------------|--------------|
| 30849-154 | 4HP | 1 | XL | Screw-on Front | Textile | Anodized |
| 30849-155 | 8HP | 1 | XL | Screw-on Front | Textile | Anodized |
| 30849-156 | 8HP | 1 | XL | Screw-on Front | Textile | Anodized |
| 30849-157 | 12HP | 1 | XL | Screw-on Front | Textile | Anodized |
| 30849-158 | 12HP | 1 | XL | Screw-on Front | Textile | Anodized |

Table 2/3

| Catalog Number | Rear Finish | Treated Edges | Complies With | Depth (D) | Height (H) | Rack Height |
|----------------|-------------|---------------|---------------------------------|-----------|------------|-------------|
| 30849-153 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm | 261.8mm | 6U |
| 30849-154 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm | 261.8mm | 6U |
| 30849-155 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm | 261.8mm | 6U |
| 30849-156 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm | 261.8mm | 6U |
| 30849-157 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm | 261.8mm | 6U |
| 30849-158 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm | 261.8mm | 6U |

Table 3/3

| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30849-153 | 20mm | No |
| 30849-154 | 20mm | No |
| 30849-155 | 40.3mm | No |


| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30849-156 | 40.3mm | No |
| 30849-157 | 60.6mm | No |
| 30849-158 | 60.6mm | No |

ADDITIONAL PRODUCT DETAILS

Delivery is exclusively in standard pack quantity, Please order EMC textile gasket and microswitch separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

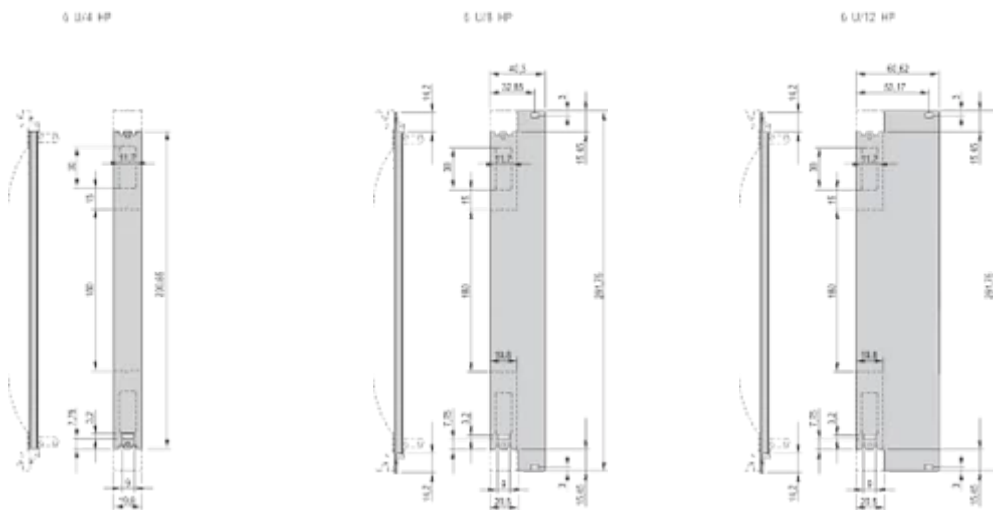

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE