


# PropacPRO Rear Hood

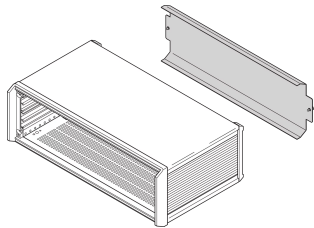

The rear hood can be assembled onto a rear panel of a PropacPRO case. The rear hood enables an additional space between the rear panel and the hood to provide space to store a cable. Can be unscrewed from the rear side.

## CERTIFICATIONS



## FEATURES

Al material 1.0 mm, RAL 9006

The fixing is done with two knurled screws

## SPECIFICATIONS

|                        |               |
|------------------------|---------------|
| <b>Material:</b>       | Aluminum      |
| <b>Works With:</b>     | Cases         |
| <b>Product Type:</b>   | Cover         |
| <b>Finish:</b>         | Powder Coated |
| <b>Product Family:</b> | PropacPRO     |
| <b>Type:</b>           | Rear Hood     |

Table 1/1

| Catalog Number | Rack Height | Rack Width | Package Quantity | Quick Ship |
|----------------|-------------|------------|------------------|------------|
| 24576-086      | 3U          | 42HP       | 1                | No         |
| 24576-087      | 3U          | 63HP       | 1                | No         |
| 24576-091      | 4U          | 63HP       | 1                | No         |

| Catalog Number | Rack Height | Rack Width | Package Quantity | Quick Ship |
|----------------|-------------|------------|------------------|------------|
| 24576-088      | 3U          | 84HP       | 1                | No         |
| 24576-092      | 4U          | 84HP       | 1                | No         |

## ADDITIONAL PRODUCT DETAILS

To install the rear hood, feet must be fitted to the rear panel; please order separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**