


# Varistar Cable Support Rail for Cabinet Depth

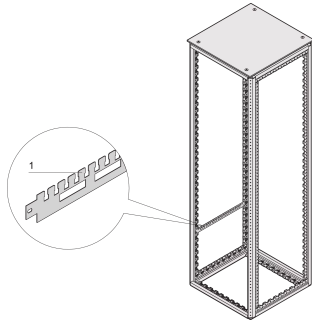

Varistar horizontal cable support rail in the cabinet depth.  
Mounted directly at the frame.

## CERTIFICATIONS



## FEATURES

For cable shells (bottom row) and for cable ties or Velcro (top row)

For cable ducting in side area of cabinet

## SPECIFICATIONS

**Material:** Steel  
**Product Type:** Support Rail

Table 1/2

Catalog Number	Depth	Package Quantity	Color	Color Code	Finish	Length
23130-326	600mm	2	Black Grey	RAL 7021	Powder Coated	466.4mm
23130-328	800mm	2	Black Grey	RAL 7021	Powder Coated	666.4mm
23130-329	900mm	2	Black Grey	RAL 7021	Powder Coated	766.4mm

CatalogNumber	Depth	Package Quantity	Color	Color Code	Finish	Length
23130-330	1000mm	2	Black Grey	RAL 7021	Powder Coated	866.4mm
23130-331	1100mm	2	Black Grey	RAL 7021	Powder Coated	966.4mm
23130-332	1200mm	2	Black Grey	RAL 7021	Powder Coated	1066.4mm
22130-605	1000mm		Light Grey	RAL 7035		866.4mm
22130-606	1100mm		Light Grey	RAL 7035		966.4mm
22130-607	1200mm		Light Grey	RAL 7035		1066.4mm

Table 2/2

Catalog Number	Type	Works With	Certifications	Quick Ship
23130-326	Cable Support, Side Mount		RoHS	No
23130-328	Cable Support, Side Mount		RoHS	No
23130-329	Cable Support, Side Mount		RoHS	No
23130-330	Cable Support, Side Mount	Varistar CP	RoHS	No
23130-331	Cable Support, Side Mount	Varistar CP	RoHS	No
23130-332	Cable Support, Side Mount	Varistar CP	RoHS	No
22130-605	Cable Support, Side Mount			No
22130-606	Cable Support, Side Mount			No
22130-607	Cable Support, Side Mount			No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**