

C-Channel U-Shaped Washer



FEATURES

U-shaped wrap around washer

For use with C-Profiles

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	A	B	C	Thickness (T)	Hole Size (HS)
PLNE010	588250	28 mm	30 mm	15 mm	2 mm	10.5 mm
PLNE1208	588260	31 mm	30 mm	13.5 mm	2 mm	8.5 mm
PLNE008	588240	28 mm	30 mm	15 mm	2 mm	8.5 mm
PLNE3410	588285	39 mm	30 mm	17.5 mm	3 mm	10.5 mm
PLNE3408	588280	39 mm	30 mm	17.5 mm	3 mm	8.5 mm
PLUNI10	588290	35 mm	30 mm	10 mm	3 mm	10.5 mm

Table 2/2

Catalog Number	Article Number	Channel Type
PLNE010	588250	E0, E0L
PLNE1208	588260	E0L, E0, E1
PLNE008	588240	E0, E0L
PLNE3410	588285	E2, E3, E4
PLNE3408	588280	E2, E3, E4
PLUN110	588290	E1, E2, E2L

DIAGRAMS

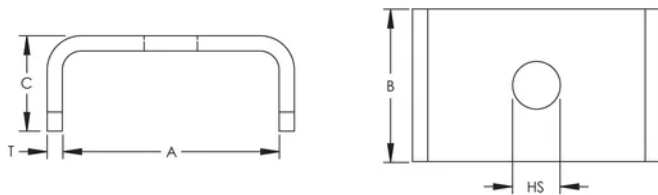

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

