


# nVent CADDY Speed Link SLK with Decking Hook



## CERTIFICATIONS

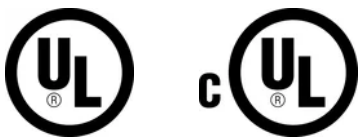

## FEATURES

Complete system includes wire, locking device and pre-assembled decking hook end fitting

Quickly and easily attaches to hollow metal decking

Spring-loaded ends snap into decking hole and lock into place

Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire

## SPECIFICATIONS

|                                   |                                |
|-----------------------------------|--------------------------------|
| <b>Static Load Safety Factor:</b> | 5:1                            |
| <b>Finish:</b>                    | Electrogalvanized              |
| <b>Material:</b>                  | Steel;Zinc Alloy;Polypropylene |
| <b>Complies With:</b>             | SMACNA HVAC-DCS                |

Table 1/2

| Catalog Number | Article Number | Wire Rope Diameter | Wire Rope Length | Roof Decking Sheet Thickness | A | Hole Size (HS) |
|----------------|----------------|--------------------|------------------|------------------------------|---|----------------|
|----------------|----------------|--------------------|------------------|------------------------------|---|----------------|

|           |        |        |    |            |        |      |
|-----------|--------|--------|----|------------|--------|------|
| SLK15L2DH | 196677 | 1.5 mm | 2m | 1.5 mm Max | 9.2 mm | 8 mm |
| SLK2L3DH  | 196532 | 2 mm   | 3m | 1.5 mm Max | 9.2 mm | 8 mm |
| SLK2L7DH  | 196534 | 2 mm   | 7m | 1.5 mm Max | 9.2 mm | 8 mm |
| SLK15L5DH | 196505 | 1.5 mm | 5m | 1.5 mm Max | 9.2 mm | 8 mm |
| SLK15L3DH | 196504 | 1.5 mm | 3m | 1.5 mm Max | 9.2 mm | 8 mm |
| SLK2L5DH  | 196533 | 2 mm   | 5m | 1.5 mm Max | 9.2 mm | 8 mm |
| SLK15L1DH | 196676 | 1.5 mm | 1m | 1.5 mm Max | 9.2 mm | 8 mm |

Table 2/2

| Catalog Number | Article Number | Static Load |
|----------------|----------------|-------------|
| SLK15L2DH      | 196677         | 195N        |
| SLK2L3DH       | 196532         | 440N        |
| SLK2L7DH       | 196534         | 440N        |
| SLK15L5DH      | 196505         | 195N        |
| SLK15L3DH      | 196504         | 195N        |
| SLK2L5DH       | 196533         | 440N        |
| SLK15L1DH      | 196676         | 195N        |

**Thickness (T):** 12.5 mm

**Width (W):** 19 mm

**Height (H):** 55 mm


**Angle (a):** 90 ° Max

ADDITIONAL PRODUCT DETAILS

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

DIAGRAMS

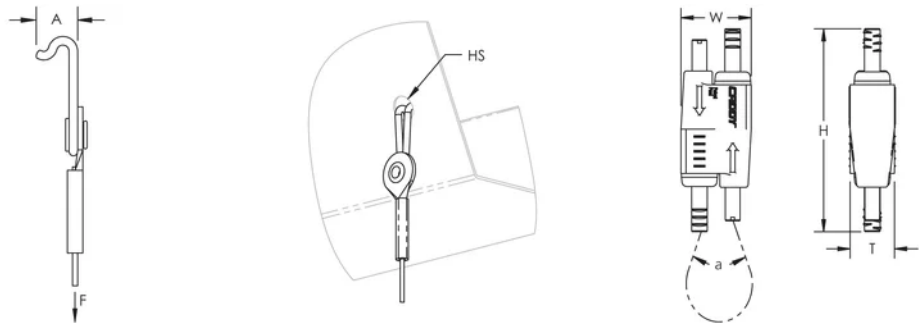

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

