

# nVent CADDY Speed Link SLK with Wedge Anchor



## FEATURES

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

## SPECIFICATIONS

|                                   |                                |
|-----------------------------------|--------------------------------|
| <b>Static Load Safety Factor:</b> | 5:1                            |
| <b>Drill Bit Diameter:</b>        | 6mm                            |
| <b>Drill Hole Depth:</b>          | 31mm                           |
| <b>Embedment Depth:</b>           | 25 mm Min                      |
| <b>Finish:</b>                    | Electrogalvanized              |
| <b>Material:</b>                  | Steel;Polypropylene;Zinc Alloy |

Table 1/2


| Catalog Number | Article Number | Wire Rope Diameter | Wire Rope Length | Length (L) | Height (H) | Width (W) |
|----------------|----------------|--------------------|------------------|------------|------------|-----------|
| SLK3L2WA6      | 196723         | 3 mm               | 2m               | 63.5mm     | 62 mm      | 24 mm     |
| SLK3L5WA6      | 196725         | 3 mm               | 5m               | 63.5mm     | 62 mm      | 24 mm     |

| CatalogNumber | Article Number | Wire Rope Diameter | Wire Rope Length | Length (L) | Height (H) | Width (W) |
|---------------|----------------|--------------------|------------------|------------|------------|-----------|
| SLK2L3WA6     | 196735         | 2 mm               | 3m               | 54mm       | 55 mm      | 19 mm     |
| SLK15L1WA6    | 196670         | 1.5 mm             | 1m               | 63.5mm     | 55 mm      | 19 mm     |
| SLK15L2WA6    | 196671         | 1.5 mm             | 2m               | 54mm       | 55 mm      | 19 mm     |
| SLK2L2WA6     | 196734         | 2 mm               | 2m               | 54mm       | 55 mm      | 19 mm     |
| SLK15L5WA6    | 196673         | 1.5 mm             | 5m               | 63.5mm     | 55 mm      | 19 mm     |
| SLK15L3WA6    | 196672         | 1.5 mm             | 3m               | 54mm       | 55 mm      | 19 mm     |
| SLK2L5WA6     | 196736         | 2 mm               | 5m               | 63.5mm     | 55 mm      | 19 mm     |

Table 2/2

| Catalog Number | Article Number | Thickness (T) | Angle (a) | Static Load |
|----------------|----------------|---------------|-----------|-------------|
| SLK3L2WA6      | 196723         | 16 mm         | 90 ° Max  | 800N        |
| SLK3L5WA6      | 196725         | 16 mm         | 90 ° Max  | 800N        |
| SLK2L3WA6      | 196735         | 12.5 mm       | 90 ° Max  | 300N        |
| SLK15L1WA6     | 196670         | 12.5 mm       | 90 ° Max  | 195N        |
| SLK15L2WA6     | 196671         | 12.5 mm       | 90 ° Max  | 195N        |
| SLK2L2WA6      | 196734         | 12.5 mm       | 90 ° Max  | 300N        |
| SLK15L5WA6     | 196673         | 12.5 mm       | 90 ° Max  | 195N        |
| SLK15L3WA6     | 196672         | 12.5 mm       | 90 ° Max  | 195N        |
| SLK2L5WA6      | 196736         | 12.5 mm       | 90 ° Max  | 440N        |

DIAGRAMS

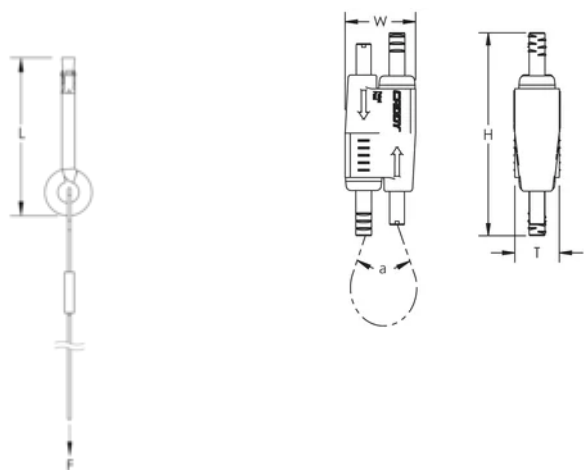

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

