

Tape Clamp



FEATURES

Secures lightning protection conductors and prevents displacement

Mechanically secured with screws or nails

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Tape Size	Tape Type	Depth (D)	Height (H)
DCA253	711730	Aluminum	25 x 3 mm	Bare	20mm	10 mm
DCA600	711760	Aluminum	25 x 3 mm	Insulated	20mm	13 mm
DCC316	711660	Brass	31 x 6 mm	Bare	18mm	13 mm
DCC256	711230	Brass	25 x 6 mm	Bare	20mm	14 mm
DCC506	711240	Brass	50 x 6 mm	Bare	20mm	13 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Hole Size (HS)	Complies With	Unit Weight
DCA253	711730	50 mm	7 mm	IEC® 62561-4, EN IEC 62561-4:2017	0.03 kg

Catalog Number	Article Number	Width (W)	Hole Size (HS)	Complies With	Unit Weight
DCA600	711760	52 mm	7 mm		0.04 kg
DCC316	711660	56 mm	7 mm		0.067 kg
DCC256	711230	50 mm	7 mm		0.08 kg
DCC506	711240	75 mm	7 mm		0.16 kg

DIAGRAMS

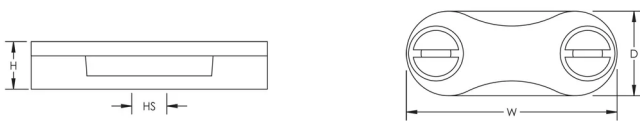

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE