


# Novastar 19" Shelf, Stationary

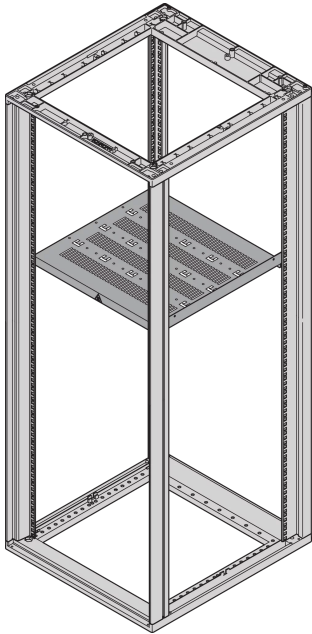

Novastar 19" Shelf, Stationary with 75 Kg load capacity, perforated for ease of assembly.

## CERTIFICATIONS



## FEATURES

Mounting height 1 U, for fitting on the vertical cabinet uprights

Static load-carrying capacity 75 kg

Perforated for assembling cable ties

St, 1.5 mm

With perforation

Color RAL 7021

## SPECIFICATIONS

|                      |       |
|----------------------|-------|
| <b>Product Type:</b> | Shelf |
| <b>Material:</b>     | Steel |

Table 1/2

| Catalog Number | Width | Depth  | Package Quantity | Color      | Color Code | Finish        |
|----------------|-------|--------|------------------|------------|------------|---------------|
| 27230-051      | 553mm | 500mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-165      | 740mm | 900mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-089      | 553mm | 1000mm | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-053      | 553mm | 800mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-088      | 553mm | 900mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-052      | 553mm | 600mm  | 1                | Black Grey | RAL 7021   | Powder Coated |

Table 2/2

| Catalog Number | Height  | Type             | Quick Ship |
|----------------|---------|------------------|------------|
| 27230-051      | 44.45mm | Stationary Shelf | No         |
| 27230-165      | 44.45mm | Stationary Shelf | No         |
| 27230-089      | 44.45mm | Stationary Shelf | No         |
| 27230-053      | 44.45mm | Stationary Shelf | No         |
| 27230-088      | 44.45mm | Stationary Shelf | No         |
| 27230-052      | 44.45mm | Stationary Shelf | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**