

# C-ES Cable to Vertical Flange Clamp



## FEATURES

Supports single run of cable

Attaches to beam flanges, angle iron, joists and other structural supports

## SPECIFICATIONS

**Finish:** Hot-Dip Galvanized

**Material:** Steel

Table 1/1


| Catalog Number | Article Number | Outer Diameter (OD) | A     | Torque (TQ) |
|----------------|----------------|---------------------|-------|-------------|
| C12ES          | 337000         | 6 - 12 mm           | 43 mm | 2 N·m       |
| C16ES          | 337010         | 12 - 16 mm          | 43 mm | 2 N·m       |
| C20ES          | 337020         | 16 - 20 mm          | 43 mm | 2 N·m       |
| C24ES          | 337030         | 20 - 24 mm          | 43 mm | 2 N·m       |
| C28ES          | 337040         | 24 - 28 mm          | 43 mm | 2 N·m       |
| C32ES          | 337050         | 28 - 32 mm          | 43 mm | 2 N·m       |

| Catalog Number | Article Number | Outer Diameter (OD) | A     | Torque (TQ) |
|----------------|----------------|---------------------|-------|-------------|
| C36ES          | 337060         | 32 - 36 mm          | 43 mm | 2 N·m       |
| C40ES          | 337070         | 36 - 40 mm          | 43 mm | 2 N·m       |
| C44ES          | 337080         | 40 - 44 mm          | 43 mm | 4 N·m       |
| C48ES          | 337090         | 44 - 48 mm          | 43 mm | 4 N·m       |
| C52ES          | 337100         | 48 - 52 mm          | 43 mm | 4 N·m       |
| C56ES          | 337110         | 52 - 56 mm          | 43 mm | 4 N·m       |
| C60ES          | 337120         | 56 - 60 mm          | 43 mm | 4 N·m       |
| C64ES          | 337130         | 60 - 64 mm          | 43 mm | 4 N·m       |

## ADDITIONAL PRODUCT DETAILS

Screw is electrogalvanized on clamps that have an outer diameter of 40 mm or less.

## DIAGRAMS

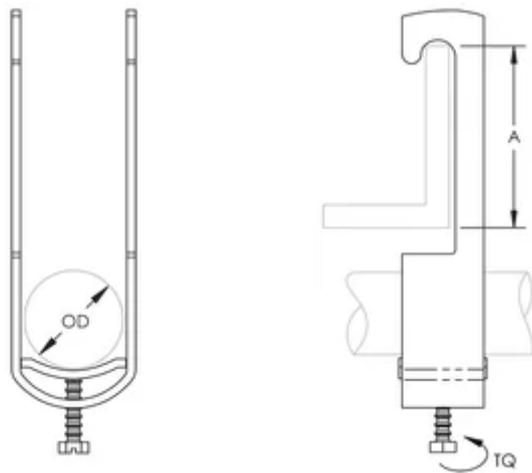

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

