

# nVent CADDY Speed Link SLK with Wedge Anchor



## FEATURES

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

## SPECIFICATIONS

|                                   |                                |
|-----------------------------------|--------------------------------|
| <b>Static Load Safety Factor:</b> | 5:1                            |
| <b>Drill Bit Diameter:</b>        | 6mm                            |
| <b>Drill Hole Depth:</b>          | 31mm                           |
| <b>Finish:</b>                    | Electrogalvanized              |
| <b>Material:</b>                  | Steel;Polypropylene;Zinc Alloy |
| <b>Embedment Depth:</b>           | 25 mm Min                      |


Table 1/2

| Catalog Number | Article Number | Wire Rope Diameter | Wire Rope Length | Length (L) | Height (H) | Width (W) |
|----------------|----------------|--------------------|------------------|------------|------------|-----------|
| SLK2L3WA6      | 196735         | 2 mm               | 3m               | 54mm       | 55 mm      | 19 mm     |
| SLK15L2WA6     | 196671         | 1.5 mm             | 2m               | 54mm       | 55 mm      | 19 mm     |

| CatalogNumber | Article Number | Wire Rope Diameter | Wire Rope Length | Length (L) | Height (H) | Width (W) |
|---------------|----------------|--------------------|------------------|------------|------------|-----------|
| SLK2L2WA6     | 196734         | 2 mm               | 2m               | 54mm       | 55 mm      | 19 mm     |
| SLK15L3WA6    | 196672         | 1.5 mm             | 3m               | 54mm       | 55 mm      | 19 mm     |

| Table 2/2      |                |               |           |             |
|----------------|----------------|---------------|-----------|-------------|
| Catalog Number | Article Number | Thickness (T) | Angle (a) | Static Load |
| SLK2L3WA6      | 196735         | 12.5 mm       | 90 ° Max  | 300N        |
| SLK15L2WA6     | 196671         | 12.5 mm       | 90 ° Max  | 195N        |
| SLK2L2WA6      | 196734         | 12.5 mm       | 90 ° Max  | 300N        |
| SLK15L3WA6     | 196672         | 12.5 mm       | 90 ° Max  | 195N        |

## DIAGRAMS

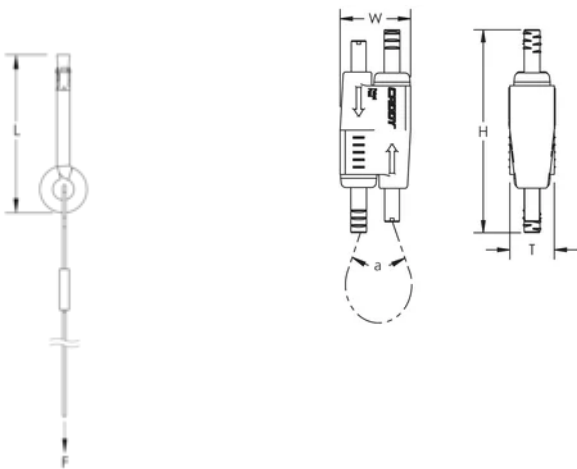

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

