

# Ground Rod Clamp, Rod to Conductor, Bronze



## CERTIFICATIONS



## FEATURES

For use with copper-bonded ground rods

Parts that are UL 467 Listed are suitable for direct burial in earth or concrete

## SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size	Wrench Size
CP38	158155	Silicon Bronze	3/8"	9.7 mm	#10 Solid - #2 Stranded, 6 mm <sup>2</sup> Solid - 25 mm <sup>2</sup> Stranded	9/16"
C12	158260	Gunmetal	1/2"	12.5 - 12.7 mm	50 mm <sup>2</sup> Stranded Max	14 mm
CP58	158165	Silicon Bronze	1/2" - 5/8"	12.5 - 14.2 mm	#10 Solid - #2 Stranded, 6 mm <sup>2</sup> Solid - 25 mm <sup>2</sup> Stranded	3/4"


CatalogNumber	Article Number	Material	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size	Wrench Size
C58	158160	Gunmetal	1/2" - 5/8"	12.5 - 15 mm	70 mm <sup>2</sup> Stranded Max	14 mm
C19	156900	Gunmetal	5/8" - 3/4"	14.2 - 19 mm	70 mm <sup>2</sup> Stranded Max	14 mm
C200	156910	Gunmetal	5/8" - 3/4"	14.2 - 20 mm	70 mm <sup>2</sup> Stranded Max	24 mm
C34	158170	Gunmetal	5/8" - 3/4"	14.2 - 17.2 mm	70 mm <sup>2</sup> Stranded Max	14 mm
HDC1	158250	Silicon Bronze	1"	25.4 mm	#8 Solid - 4/0 Stranded, 10 mm <sup>2</sup> Solid - 95 mm <sup>2</sup> Stranded	13/16"

Table 2/2

Catalog Number	Article Number	Complies With	Torque (TQ)	Certifications
CP38	158155		16.90 - 25.4 N·m	UL
C12	158260		25 N·m Max	
CP58	158165	IEC® EN 62561-1	16.90 - 25.4 N·m	UL, CSA-US, RUS, CSA, cUL
C58	158160	IEC® EN 62561-1	25 N·m Max	
C19	156900		25 N·m Max	
C200	156910		25 N·m Max	
C34	158170	IEC® EN 62561-1	25 N·m Max	
HDC1	158250		50.8 N·m	UL, cUL

## DIAGRAMS

---

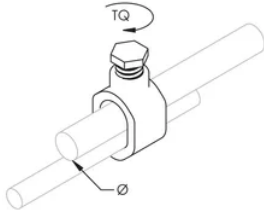

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**