


Ground Rod Clamp, Rod to Conductor, Stainless Steel



CERTIFICATIONS

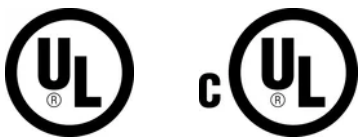

FEATURES

Unique stamped body design will not crack from excessive torque

Provides a greater surface area contact to allow improved performance of the connector

Compatible with copper, copper bonded, galvanized, stainless steel, rebar and plain steel ground rods and electrodes

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Torque (TQ)	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size
SP58	158185	Stainless Steel 304 (EN 1.4301)	16.90 - 33.9 N·m	1/2" - 5/8"	12.7 - 15.9 mm	#10 Stranded - #2 Stranded, 6 mm² Stranded - 25 mm² Stranded

Table 2/2

Catalog Number	Article Number	Wrench Size
SP58	158185	1/2"

DIAGRAMS

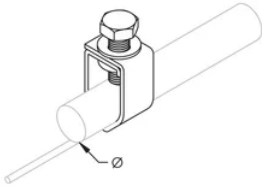

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE