

# MOV/GDT/SAD Tester



nVent ERICO testers are designed for rapid testing of the integrity of surge protection device components. Because standard metal oxide varistors, gas arresters, and avalanche diodes do not provide the user with a visual indication of the integrity of the protection capacity, an external means of testing is required. It is impossible to predict when these failures will occur without some form of testing. As MOVs approach the end of their life cycle, they exhibit a change in tolerance levels. nVent ERICO testing products are specifically designed to identify these situations and allow the operator to effect remedial replacement to the devices which are nearing the end of their life cycle. They can test both components, as well as replacement modules such as the TDS or DSD.

## CERTIFICATIONS



## FEATURES

Measurement of metal oxide varistors, gas discharge tubes, and avalanche diodes

Ability to display up to 50 measurements

Adjustable test settings

Rechargeable battery

## SPECIFICATIONS

Table 1/2


| Catalog Number | Test Voltage | GDT Voltage Ramp | MOV/SAD Test Current | Enclosure Rating | Temperature  | Depth (D) |
|----------------|--------------|------------------|----------------------|------------------|--------------|-----------|
| MGATESTER1     | 1500 Max     | 100, 1000        | 0.1kA, 0.5kA, 1kA    | IP 20            | -10 to 50 °C | 82mm      |

Table 2/2

| Catalog Number | Height (H) | Width (W) | Unit Weight |
|----------------|------------|-----------|-------------|
|----------------|------------|-----------|-------------|

|            |        |        |         |
|------------|--------|--------|---------|
| MGATESTER1 | 205 mm | 220 mm | 0.95 kg |
|------------|--------|--------|---------|

### DIAGRAMS

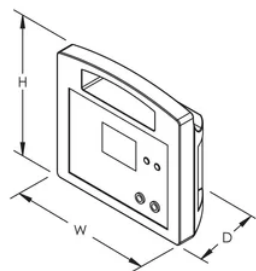

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE