


Eurorack Side Panel With Side Panel Catches

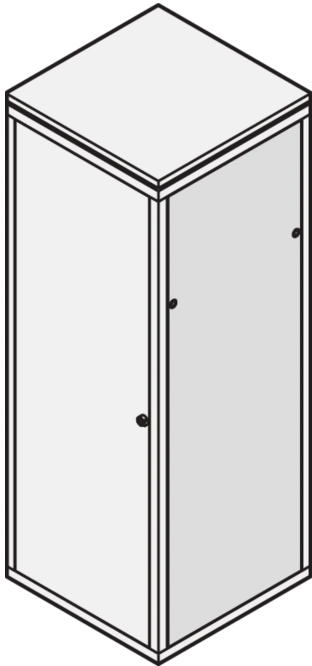

Steel Side Panels for aluminum frame with quick fastner for easy mounting and installation.

CERTIFICATIONS



FEATURES

Assembly to frame with 2 side panel catches

St, 1 mm

SPECIFICATIONS

Product Type: Cabinet/Rack Panel

Material: Steel

Table 1/2

Catalog Number	Rack Height	Height	Depth	Package Quantity	Color	Color Code
----------------	-------------	--------	-------	------------------	-------	------------

21117-158	20U	998mm	600mm	2	Light Grey	RAL 7035
21117-159	25U	1220mm	600mm	2	Light Grey	RAL 7035
21117-160	29U	1398mm	600mm	2	Light Grey	RAL 7035
21117-161	34U	1567mm	600mm	2	Light Grey	RAL 7035
21117-162	38U	1798mm	600mm	2	Light Grey	RAL 7035
21117-163	43U	2020mm	600mm	2	Light Grey	RAL 7035
21117-164	47U	2198mm	600mm	2	Light Grey	RAL 7035
21117-167	20U	998mm	800mm	2	Light Grey	RAL 7035
21117-168	25U	1220mm	800mm	2	Light Grey	RAL 7035
21117-169	29U	1398mm	800mm	2	Light Grey	RAL 7035
21117-170	34U	1567mm	800mm	2	Light Grey	RAL 7035
21117-171	38U	1798mm	800mm	2	Light Grey	RAL 7035
21117-172	43U	2020mm	800mm	2	Light Grey	RAL 7035
21117-173	47U	2198mm	800mm	2	Light Grey	RAL 7035
21117-179	34U	1567mm	900mm	2	Light Grey	RAL 7035
21117-180	38U	1798mm	900mm	2	Light Grey	RAL 7035
21117-181	43U	2020mm	900mm	2	Light Grey	RAL 7035
21117-182	47U	2198mm	900mm	2	Light Grey	RAL 7035
22117-958	34U	1567mm	600mm	2	Black Grey	RAL 7021

22117-959	34U	1567mm	800mm	2	Black Grey	RAL 7021
22117-960	34U	1567mm	900mm	2	Black Grey	RAL 7021
22117-961	38U	1798mm	600mm	2	Black Grey	RAL 7021
22117-962	38U	1798mm	800mm	2	Black Grey	RAL 7021
22117-963	38U	1798mm	900mm	2	Black Grey	RAL 7021
22117-964	43U	2020mm	600mm	2	Black Grey	RAL 7021
22117-965	43U	2020mm	800mm	2	Black Grey	RAL 7021
22117-966	43U	2020mm	900mm	2	Black Grey	RAL 7021
22117-967	47U	2198mm	800mm	2	Black Grey	RAL 7021
22117-993	20U	998mm	600mm	2	Black Grey	RAL 7021
22117-994	20U	998mm	800mm	2	Black Grey	RAL 7021
22117-995	25U	1220mm	600mm	2	Black Grey	RAL 7021
22117-996		1220mm	800mm	2	Black Grey	RAL 7021
22117-997	29U	1398mm	600mm	2	Black Grey	RAL 7021
22117-998	29U	1398mm	800mm	2	Black Grey	RAL 7021
22117-999	47U	2198mm	600mm	2	Black Grey	RAL 7021
23117-001	47U	2198mm	900mm	2	Black Grey	RAL 7021

Table 2/2

Catalog Number	Finish	Type	Quick Ship
21117-158	Powder Coated	Side Panel	No

Catalog Number	Finish	Type	Quick Ship
21117-159	Powder Coated	Side Panel	No
21117-160	Powder Coated	Side Panel	No
21117-161	Powder Coated	Side Panel	No
21117-162	Powder Coated	Side Panel	No
21117-163	Powder Coated	Side Panel	No
21117-164	Powder Coated	Side Panel	No
21117-167	Powder Coated	Side Panel	No
21117-168	Powder Coated	Side Panel	No
21117-169	Powder Coated	Side Panel	No
21117-170	Powder Coated	Side Panel	No
21117-171	Powder Coated	Side Panel	No
21117-172	Powder Coated	Side Panel	No
21117-173	Powder Coated	Side Panel	No
21117-179	Powder Coated	Side Panel	No
21117-180	Powder Coated	Side Panel	No
21117-181	Powder Coated	Side Panel	No
21117-182	Powder Coated	Side Panel	No
22117-958	Powder Coated	Side Panel	No

Catalog Number	Finish	Type	Quick Ship
22117-959	Powder Coated	Side Panel	No
22117-960	Powder Coated	Side Panel	No
22117-961	Powder Coated	Side Panel	No
22117-962	Powder Coated	Side Panel	No
22117-963	Powder Coated	Side Panel	No
22117-964	Powder Coated	Side Panel	No
22117-965	Powder Coated	Side Panel	No
22117-966	Powder Coated	Side Panel	No
22117-967	Powder Coated	Side Panel	No
22117-993	Powder Coated	Side Panel	No
22117-994	Powder Coated	Side Panel	No
22117-995	Powder Coated	Side Panel	No
22117-996	Powder Coated	Side Panel	No
22117-997	Powder Coated	Side Panel	No
22117-998	Powder Coated	Side Panel	No
22117-999	Powder Coated	Side Panel	No
23117-001	Powder Coated	Side Panel	No

ADDITIONAL PRODUCT DETAILS

Instead of a side panel all doors can be laterally assembled.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE