

nVent CADDY Cat HP J-Hook Tree, Wall Mount



FEATURES

Ideal for attaching to concrete, steel or wood surfaces

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Ready to use out of the box, saving installation time and labor

Requires no screws, rivets or special tools for assembly

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

SPECIFICATIONS

Finish: Pregalvanized

Type: Single Sided

Material: Steel

Table 1/2

Catalog Number	Article Number	Diameter (Ø)	Tiers	Height (H)	Width (W)	Hole Size (HS)
CAT64HPSWM 2	181029	100 mm	2	495.3 mm	50 mm	6.5 mm
CAT32HPSWM 4	181028	50 mm	4	622.3 mm	50 mm	6.5 mm

CatalogNumber	Article Number	Diameter (Ø)	Tiers	Height (H)	Width (W)	Hole Size (HS)
CAT64HPSWM 3	181031	100 mm	3	685.8 mm	50 mm	6.5 mm
CAT32HPSWM 3	181027	50 mm	3	495.3 mm	50 mm	6.5 mm
CAT32HPSWM 2	181026	50 mm	2	368.3 mm	50 mm	6.5 mm
CAT64HPSWM 4	181032	100 mm	4	876.3 mm	50 mm	6.5 mm

Table 2/2


Catalog Number	Article Number	Static Load	Depth (D)
CAT64HPSWM2	181029	530N	139.69mm
CAT32HPSWM4	181028	1068N	86.38mm
CAT64HPSWM3	181031	800N	139.69mm
CAT32HPSWM3	181027	800N	86.38mm
CAT32HPSWM2	181026	530N	86.38mm
CAT64HPSWM4	181032	1068N	139.69mm

ADDITIONAL PRODUCT DETAILS

Static loads represent maximum load limit of J-Hook tree. Static load limit of each J-Hook is 60 lb (270 N).

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

DIAGRAMS

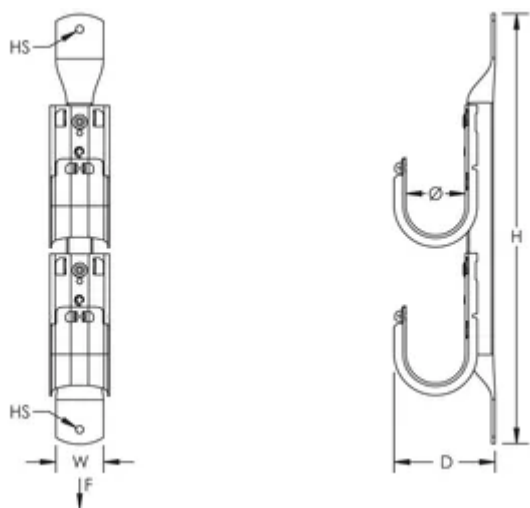

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

