


# nVent CADDY Speed Link Y-Hook with Eyelet Extension

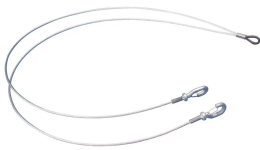

## CERTIFICATIONS



## FEATURES

Double hook offers easy attachment to basket tray, cable tray or lighting

Convenient design allows one hook to be temporarily detached for maintenance or to add cables to the tray

Y-design provides improved stability

Spring latch helps provide secure connection

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel

Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	C
SLD2YH500	196015	2 mm	0.5m	58.4 mm	22.9 mm	6 mm

CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	C
SLD3YH500	196017	3 mm	0.5m	58.4 mm	22.9 mm	6 mm
SLD3YH800	195998	3 mm	0.8m	58.4 mm	22.9 mm	6 mm



Table 2/2

Catalog Number	Article Number	Static Load	Certifications
SLD2YH500	196015	440N	UL, cUL, ITB
SLD3YH500	196017	880N	UL, cUL
SLD3YH800	195998	880N	UL, ITB, cUL

## ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

## DIAGRAMS

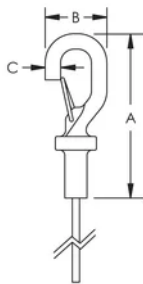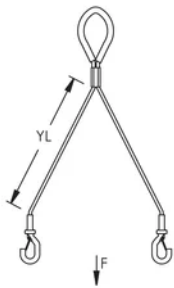

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

