

# nVent CADDY Speed Link Y-Toggle with Eyelet Extension



## CERTIFICATIONS



## FEATURES

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Y-design provides improved stability

## SPECIFICATIONS

**Static Load Safety Factor:** 5:1  
**Finish:** Electrogalvanized  
**Material:** Steel

Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load
SLD15Y200	195999	1.5 mm	0.2m	39 mm	5 mm	195N

CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load
SLD15Y300	196000	1.5 mm	0.3m	39 mm	5 mm	195N
SLD15Y500	195960	1.5 mm	0.5m	39 mm	5 mm	195N
SLD2Y300	196036	2 mm	0.3m	42 mm	8 mm	440N
SLD2Y500	176870	2 mm	0.5m	42 mm	8 mm	440N


Table 2/2

Catalog Number	Article Number	Certifications
SLD15Y200	195999	UL, cUL
SLD15Y300	196000	cUL, UL
SLD15Y500	195960	UL, cUL, ITB
SLD2Y300	196036	cUL, UL
SLD2Y500	176870	UL, ITB, cUL

## ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

## DIAGRAMS

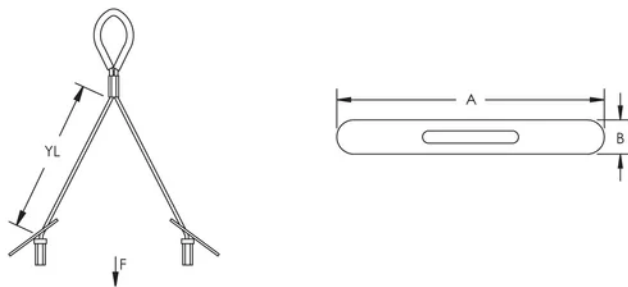

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

