


Extension Rod, Imperial Thread

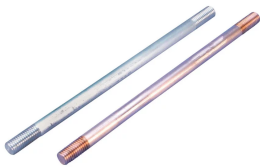

CERTIFICATIONS



FEATURES

Threaded on both ends for use as an extension rod from air terminal base to coupler or safety ball terminal

Available in configured-to-order lengths

UL listed for a minimum length of 10" (254mm)

SPECIFICATIONS


Table 1/1				
Catalog Number	Material	Thread Size (TS)	Diameter (Ø)	Certifications
LPC271CTO	Copper	3/8" UNC	9.53 mm	E202878-Combined_CoC, E202878-Combined_CoC
LPA272CTO	Aluminum	1/2" UNC	12.74 mm	
LPC272CTO	Copper	1/2" UNC	12.74 mm	
LPS273CTO	Stainless Steel 304 (EN 1.4301)	5/8" UNC	15.88 mm	

Catalog Number	Material	Thread Size (TS)	Diameter (Ø)	Certifications
LPA273CTO	Aluminum	5/8" UNC	15.88 mm	E202878-Combined_CoC, E202878-Combined_CoC
LPC273CTO	Copper	5/8" UNC	15.88 mm	E202878-Combined_CoC, E202878-Combined_CoC

ADDITIONAL PRODUCT DETAILS

Configured-to-order (CTO) lengths are available up to 144" (3,657 mm).

DIAGRAMS

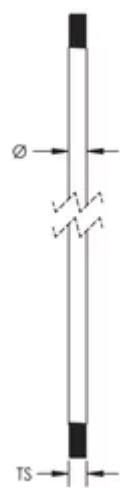

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE