

# DRG Asymmetric Profile



## CERTIFICATIONS



## FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50035 and DIN 46277

RoHS compliant

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel



Table 1/2

Catalog Number	Article Number	Height (H)	Width (W)	Length (L)	Thickness (T)	A
DRG2M	558000	32 mm	15 mm	2000mm	1.5 mm	9 mm
DRG3M	558010	32 mm	15 mm	3000mm	1.5 mm	9 mm

Table 2/2

Catalog Number	Article Number	Unit Weight
DRG2M	558000	1.4 kg
DRG3M	558010	2.1 kg

## DIAGRAMS

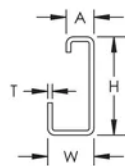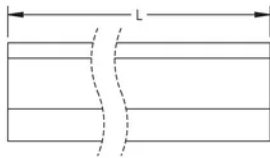

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE