

# nVent ERIFLEX Flexbus Transformer Cover IP2X for 1 Conductor per Phase



## CERTIFICATIONS



## FEATURES

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

## SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Working Temperature	Length (L)	Width (W)	Depth (D)
FLEXCOVIP2X0 NE	508160	Polyvinylchloride	-40 to 140 °C	465mm	182 mm	126mm

Table 2/2

Catalog Number	Article Number	Unit Weight
----------------	----------------	-------------

FLEXCOVIP2XONE	508160	0.53 kg
----------------	--------	---------

## DIAGRAMS

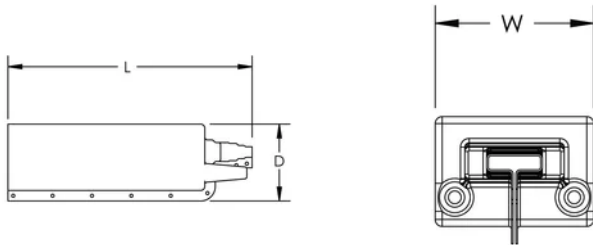

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**