


# Cable Entry Gland Plate Connected Grommet Large, CCFGL

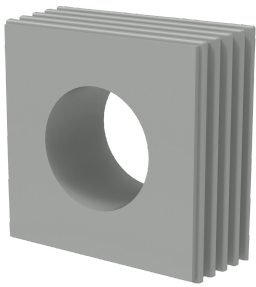

CCFG grommets are used together with the CCFI and CCFO cable entry systems. The tapered shape of the grommet makes it easy to press in the grommet. The wave-cut profile makes them easy to install and ensures a tight fit around the individual cables.

## INDUSTRY STANDARDS

UL 508A Component Recognized; Type 1, 12, 4X (indoor only); File No. E61997

UL94 V-0 Flammability

NEMA Type 1, 12, 4X (indoor only)

CE

IP66

## FEATURES

Finish: Gray

Pack quantity: 10

Description: The CCFG system is available in two sizes: small and large. The conical shape of the grommets allows them to be easily pressed in and provides static strain relief in accordance with DIN EN 62444. For assembly, they are pressed from the inside out into the openings of the assembled inlays. The grommets are available in two different sizes to match the diameter of the cable. The CCFG is first placed around the cable and then inserted into the cable gland. Thanks to the wave-cut profile, there is no need to remove the connector on the assembled cabled.

Temperature resistance: -40°C to +90°C

Flammability: UL94 V-0

Protection: IP66, NEMA 1, 4x, 12 (Indoor use only)

Material: TPE

Large Grommets available with different hole sizes to match cable diameter

Grommet is placed around cable and then inserted into cable gland

## SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Height	Width	Depth	Material	Finish
CCFGL14	58354	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL34	58376	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL33	58375	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL32	58374	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL31	58373	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL30	58372	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL29	58371	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL28	58369	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL27	58368	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL26	58367	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL24	58365	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL25	58366	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL23	58364	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL22	58363	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL21	58362	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL18	58358	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL20	58361	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL19	58359	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL17	58357	42.8mm	42.8mm	17.7mm	Plastic	Untreated

Catalog Number	Article Number	Height	Width	Depth	Material	Finish
CCFGL16	58356	42.8mm	42.8mm	17.7mm	Plastic	Untreated
CCFGL15	58355	42.8mm	42.8mm	17.7mm	Plastic	Untreated

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**