


Remote Door Switch, 120/250VAC 10Amp, Galvanized, Steel

CATALOG NUMBER

ALFSWD

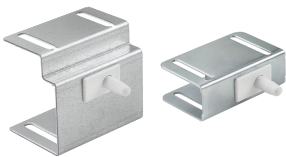

The Remote Door Switch can activate a light or other electrical component when the enclosure door is opened.

INDUSTRY STANDARDS

UL508A Recognized, Type 3R, 4, 4X, 12; File E61997

cUL Recognized per CSA C22.2 No. 14-13; Type 3R, 4, 4X, 12; File E61997

FEATURES

Mounts on enclosure frame and includes mounting hardware

Mounting plate is 14 gauge

PRODUCT ATTRIBUTES

Article Number: 71260

Height: 32mm

Width: 17mm

Depth: 22mm

Material: Mild Steel

Finish: Galvanized

Thickness: 1.9mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE