


EuropacPRO 19" Bracket for Textile Gasket, Type F

Power Utilities

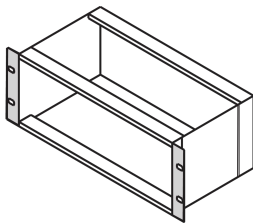

19 inch bracket Kits can be combined with the side panel type F. Available for textile EMC gaskets and with / without handle holes.

CERTIFICATIONS



FEATURES

19" bracket is bolted laterally with the side panel to the horizontal rail

For textile EMC gasket

SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Package Quantity	Material	Product Family	Product Type	Type
24564-498	6 U	1	Aluminum	EuropacPRO	Bracket	Type F
24564-297	4 U	1	Aluminum	EuropacPRO	Bracket	Type F
24564-197	3 U	1	Aluminum	EuropacPRO	Bracket	Type F

CatalogNumber	Rack Height	Package Quantity	Material	Product Family	Product Type	Type
24564-798	9 U	1	Aluminum	EuropacPRO	Bracket	Type F
24564-298	4 U	1	Aluminum	EuropacPRO	Bracket	Type F
24564-497	6 U	1	Aluminum	EuropacPRO	Bracket	Type F
24564-198	3 U	1	Aluminum	EuropacPRO	Bracket	Type F
24564-797	9 U	1	Aluminum	EuropacPRO	Bracket	Type F

Table 2/2

Catalog Number	Works With	Package Unit
24564-498	Subracks	Pair
24564-297	Subracks	Pair
24564-197	Subracks	Pair
24564-798	Subracks	Pair
24564-298	Subracks	Pair
24564-497	Subracks	Pair
24564-198	Subracks	Pair
24564-797	Subracks	Pair

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE