


# EuropacPRO Perforated Rail for Connector

## Power Utilities

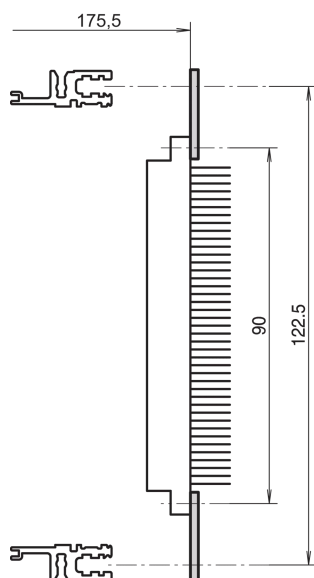

Perforated flat rail for connector mounting i.a.w. EN 60603-2 and DIN 41612, on VT horizontal rails.

## CERTIFICATIONS



## FEATURES

In conjunction with rear horizontal rails, VT

For Connector Mounting in accordance with EN 60603-2, DIN 41612

## SPECIFICATIONS

Table 1/2

| Catalog Number | Rack Width | Package Quantity | Length | Product Family | Product Type | Works With |
|----------------|------------|------------------|--------|----------------|--------------|------------|
|----------------|------------|------------------|--------|----------------|--------------|------------|

|           |       |   |           |                                                                               |                 |                    |
|-----------|-------|---|-----------|-------------------------------------------------------------------------------|-----------------|--------------------|
| 20822-052 | 4 HP  | 4 | 20.32 mm  | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO | Perforated Rail | Subracks,<br>Cases |
| 20822-049 | 28 HP | 4 | 142.24 mm | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO | Perforated Rail | Subracks,<br>Cases |
| 20822-048 | 84 HP | 4 | 431.8 mm  | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO | Perforated Rail | Subracks,<br>Cases |
| 20822-046 | 40 HP | 4 | 208.28 mm | EuropacPRO                                                                    | Perforated Rail | Subracks           |
| 20822-050 | 42 HP | 4 | 213.36 mm | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO | Perforated Rail | Subracks,<br>Cases |
| 20822-047 | 60 HP | 4 | 304.8 mm  | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO | Perforated Rail | Subracks,<br>Cases |
| 20822-051 | 20 HP | 4 | 106.68 mm | EuropacPRO                                                                    | Perforated Rail | Subracks           |
| 20822-053 | 8 HP  | 4 | 40.64 mm  | EuropacPRO,<br>RatiopacPRO,<br>RatiopacPRO<br>AIR,<br>CompacPRO,<br>PropacPRO | Perforated Rail | Subracks,<br>Cases |

Table 2/2

| Catalog Number | Certifications |
|----------------|----------------|
| 20822-052      |                |
| 20822-049      | RoHS           |

| Catalog Number | Certifications |
|----------------|----------------|
| 20822-048      | RoHS           |
| 20822-046      | RoHS           |
| 20822-050      | RoHS           |
| 20822-047      | RoHS           |
| 20822-051      | RoHS           |
| 20822-053      |                |

### ADDITIONAL PRODUCT DETAILS

A threaded insert is required to secure the perforated rail on the horizontal rail.

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE