

Side Receptor Plug

Power Utilities



FEATURES

Fully encapsulated connection from conductor to receptor disk

Performance tested beyond IEC® 61400-24

Superior receptor product life performance

Less than 12 °C (54 °F) temperature rise after strike of 225 kA


Simple integrated installation

SPECIFICATIONS

Table 1/1

Catalog Number	Height (H)	A
WT2SA7002.5	36 mm	146 mm

DIAGRAMS

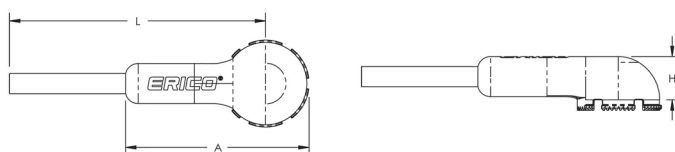

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE