


Varistar CP Seismic Base Plate, IP55 and EMC, One-Piece

The base plate is solid and covers the base of the cabinet.

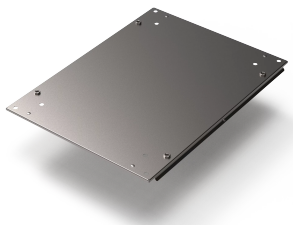

FEATURES

The base plate is solid and covers the base of the cabinet

Is assembled from outside

SPECIFICATIONS

Product Type:	Cabinet/Rack Base
Finish:	Hot-Dip Galvanized
Protection Rating:	IP55
Material:	Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Complies With	Type	Works With
20630-309	600mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP
20630-310	600mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP

CatalogNumber	Width	Depth	Package Quantity	Complies With	Type	Works With
20630-311	600mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP
20630-312	600mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP
20630-313	800mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP
20630-314	800mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP
20630-315	800mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP
20630-316	800mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3, IEC 60529	Base Plate, Plain	Varistar CP

Table 2/2

Catalog Number	Quick Ship
20630-309	No
20630-310	No
20630-311	No
20630-312	No
20630-313	No
20630-314	No
20630-315	No

Catalog Number	Quick Ship
20630-316	No

ADDITIONAL PRODUCT DETAILS

This base plate is used for applications which don't require cable entry from the base.

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE