

# nVent CADDY Cushion Clamp Insulated Strut Clamp for Pipe/Tube



## FEATURES

Fits into open side of strut channel

Plastic cushion is hinged to spread apart for easy installation

Reduces noise and absorbs shock by gripping the pipe/tube firmly

Square neck of carriage bolt prevents over-tightening

Nylon locknut prevents loosening under vibration

FM® Specification Tested (from 3/8" to 4" of Copper Tube Size)

## SPECIFICATIONS

**Material:** Steel; Polypropylene

**Finish:** Zinc Chromate

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Copper Tube Size	NB/DN	Width (W)	A
CCC0050	598884	12.7 mm	3/8"	8	39.7 mm	22.1 mm
CCC0037	598883	9.5 mm	1/4"		39.7 mm	18.9 mm
CCC0062	598886	15.8 mm	1/2"	10	39.7 mm	25.2 mm


CatalogNumber	Article Number	Outer Diameter (OD)	Copper Tube Size	NB/DN	Width (W)	A
CCC0087	598891	22.2 mm	3/4"	15	39.7 mm	31.6 mm
CCC0075	598888	19.1 mm	5/8"		39.7 mm	28.4 mm
CCC0100	598892	25.4 mm		20	39.7 mm	34.8 mm
CCC0125	598895	31.8 mm		25	39.7 mm	42.1 mm
CCC0112	598894	28.6 mm	1"		39.7 mm	39 mm
CCC0187	598903	47.6 mm		40	39.7 mm	59 mm
CCC0162	598899	41.3 mm	1 1/2"	32	39.7 mm	51.6 mm
CCC0237	598908	60.3 mm		50	39.7 mm	74.9 mm
CCC0450	598957	114.3 mm		100	39.7 mm	132 mm
CCC0212	598906	53.9 mm	2"		39.7 mm	68.5 mm

Table 2/2

Catalog Number	Article Number	B
CCC0050	598884	38.6 mm
CCC0037	598883	35.4 mm
CCC0062	598886	41.7 mm
CCC0087	598891	48.1 mm
CCC0075	598888	44.9 mm
CCC0100	598892	51.3 mm
CCC0125	598895	65.6 mm

Catalog Number	Article Number	B
CCC0112	598894	62.4 mm
CCC0187	598903	81.5 mm
CCC0162	598899	75.1 mm
CCC0237	598908	97.4 mm
CCC0450	598957	160.5 mm
CCC0212	598906	91 mm

## DIAGRAMS

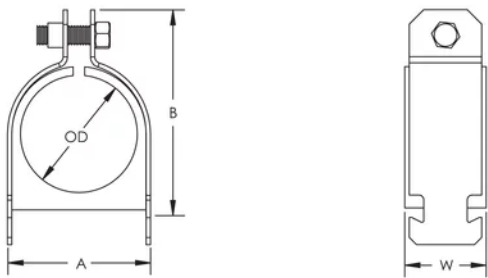

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

