


PESMOS Medium Duty Pipe Slide with Strap, One Connector

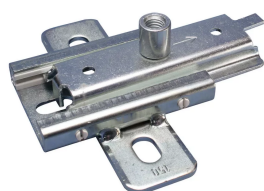

FEATURES

For use with one pipe clamp


Includes welded on mounting strap

SPECIFICATIONS

Catalog Number	PESMOS
Article Number	580561
Material	Steel Polyamide
Finish	Electrogalvanized
Rod Size (RS)	M10 M12
Height (H)	46 mm
Length (L)	122mm
Δ Length (ΔL)	80 mm
Width (W)	150 mm
A	100 mm
B	40 mm
X	12.5 x 20 mm
Temperature	120 °C Max

Catalog Number	PESMOS
Static Load 1 (F1)	2300N
Static Load 2 (F2)	2300N

DIAGRAMS

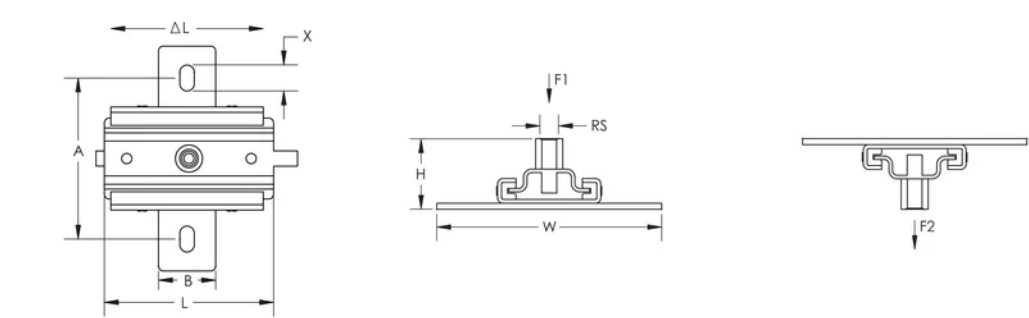

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

