


19" Front Panel, Vented

Data Solutions

Vented front panels allows heat dissipation through holes.

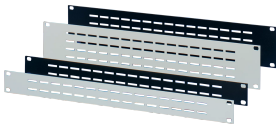

CERTIFICATIONS



FEATURES

Vented front panels (Aluminum) allows heat dissipation

SPECIFICATIONS

Rack Width:	95HP
Material:	Aluminum
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Catalog Number	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30118-962	1U	Powder Coated	Screw-on Front	1	Painted	Painted

CatalogNumber	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-056	1U	Powder Coated	Screw-on Front	1	Painted	Painted
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Powder Coated	Screw-on Front	1	Painted	Painted
30118-964	3U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-058	3U	Powder Coated	Screw-on Front	1	Painted	Painted

Table 2/2						
Catalog Number	Treated Edges	Color Code	EMC Shielding	Height (H)	Type	Width (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE