


Joint Bond T9 Mold Welder Frame Assembly, Power

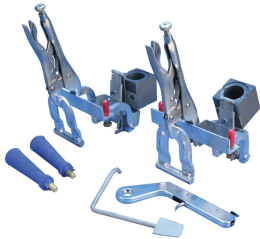

FEATURES

Replacement welder frame assembly for T9 joint bond welders

Includes frame with mold lid, mold handle, mold cleaner and flint ignitor

SPECIFICATIONS

Rail Type:	85 lb to 141 lb T-Rail Sections
Bond Terminal Style:	C
Material:	Graphite;Steel;Thermoplastic

Table 1/1

Catalog Number	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style	Orientation
PBCT92JLHX	2/0 Ropelay	12.19mm	T9	Left Hand Assembly
PBCT92JRHX	2/0 Ropelay	12.19mm	T9	Right Hand Assembly
PBCT92SLHX	4/0 Ropelay	15.49mm	T9	Left Hand Assembly
PBCT92SRHX	4/0 Ropelay	15.49mm	T9	Right Hand Assembly
PBCT92WLHX	250 kcmil Ropelay	19.05mm	T9	Left Hand Assembly

Catalog Number	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style	Orientation
PBCT92WRHX	250 kcmil Ropelay	19.05mm	T9	Right Hand Assembly
PBCT92WX	250 kcmil Ropelay	19.05mm	T9	Left and Right Hand Assembly

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE