


Eurorack Slide Rail, 40 kg, Depth-Adjustable

CATALOG NUMBER

28127-001

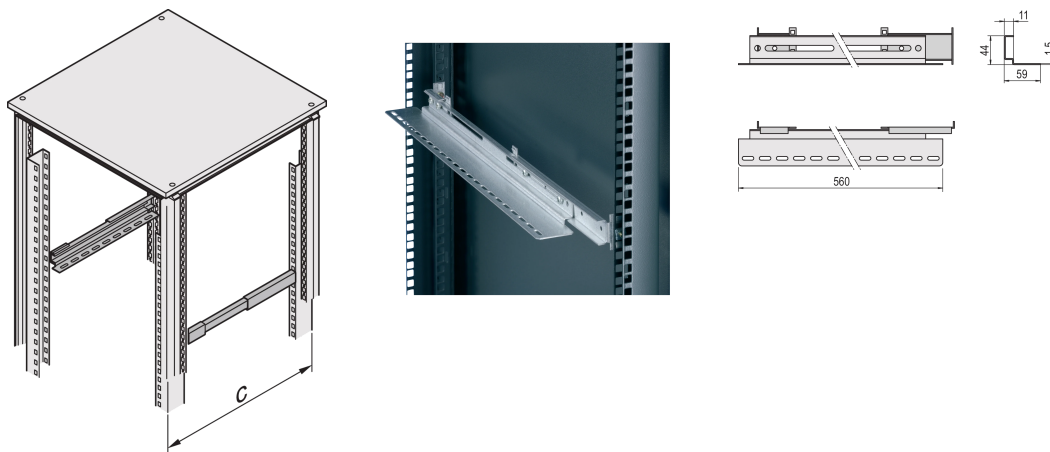

Eurorack Slide Rail with 40 kg load capacity for mounting on the cabinet uprights or 19" panel/slide mounts. The slide rail supports shelf of heavy 19" Chassis.

CERTIFICATIONS



FEATURES

Can be fitted in 1 U increments

Static load-carrying capacity 40 kg per pair, depth-adjustable

St, 1.5 mm, finish AlZn

For fitting to 19" panel/slide mounts or 19" server panel/slide mounts (pitch c from 675 mm to 850 mm)

Support for heavy 19" modules

Wide support surface

PRODUCT ATTRIBUTES

Product Type: Slide Rail

Product Family: Eurorack

Material: Steel

Finish: Aluminum-Zinc Plated

Length: 560mm

Static Load: 40kg

Package Quantity: 1

Gross Weight: 2.26kg

ADDITIONAL PRODUCT DETAILS

For rack-mounting from 800 mm depth only.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE