


# Male-Male Adaptor, Imperial Thread

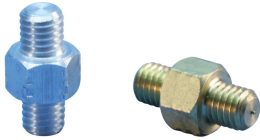

## CERTIFICATIONS



## FEATURES

Threaded adaptor with hexagonal body for ease of tightening

## SPECIFICATIONS

Table 1/2

| Catalog Number | Material                        | Thread Size 1 (TS1) | Thread Size 2 (TS2) | Height (H) | Width (W) | Unit Weight |
|----------------|---------------------------------|---------------------|---------------------|------------|-----------|-------------|
| LPS2955M5M     | Stainless Steel 304 (EN 1.4301) | 5/8" UNC            | 5/8" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPC2955M5M     | Copper                          | 5/8" UNC            | 5/8" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPA2942M5M     | Aluminum                        | 1/2" UNC            | 5/8" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPC2945M2M     | Copper                          | 5/8" UNC            | 1/2" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPA2955M5M     | Aluminum                        | 5/8" UNC            | 5/8" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |


| CatalogNumber | Material                        | Thread Size 1 (TS1) | Thread Size 2 (TS2) | Height (H) | Width (W) | Unit Weight |
|---------------|---------------------------------|---------------------|---------------------|------------|-----------|-------------|
| LPS2932M2M    | Stainless Steel 304 (EN 1.4301) | 1/2" UNC            | 1/2" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPC2932M2M    | Copper                          | 1/2" UNC            | 1/2" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPA2932M2M    | Aluminum                        | 1/2" UNC            | 1/2" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPC2913M3M    | Copper                          | 3/8" UNC            | 3/8" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPS2945M2M    | Stainless Steel 304 (EN 1.4301) | 5/8" UNC            | 1/2" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |
| LPC2922M3M    | Copper                          | 1/2" UNC            | 3/8" UNC            | 38.1 mm    | 19.1 mm   | 0.02 kg     |

Table 2/2

| Catalog Number | Certifications                             |
|----------------|--------------------------------------------|
| LPS2955M5M     |                                            |
| LPC2955M5M     | E202878-Combined_CoC, E202878-Combined_CoC |
| LPA2942M5M     | E202878-Combined_CoC, E202878-Combined_CoC |
| LPC2945M2M     | E202878-Combined_CoC, E202878-Combined_CoC |
| LPA2955M5M     |                                            |
| LPS2932M2M     |                                            |
| LPC2932M2M     | E202878-Combined_CoC, E202878-Combined_CoC |
| LPA2932M2M     | E202878-Combined_CoC, E202878-Combined_CoC |
| LPC2913M3M     | E202878-Combined_CoC, E202878-Combined_CoC |
| LPS2945M2M     |                                            |

| Catalog Number | Certifications                             |
|----------------|--------------------------------------------|
| LPC2922M3M     | E202878-Combined_CoC, E202878-Combined_CoC |

### DIAGRAMS

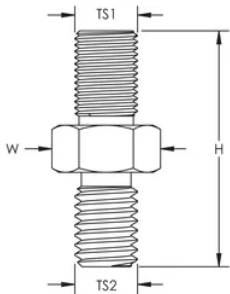

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ **WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE