

Theft-Deterrent Grounding Busbar, Pole Mount Assembly



CERTIFICATIONS



FEATURES

Mounts on a standard Schedule 40 ice bridge pole (3.5" or 88.9 mm nominal outer diameter) and provides a path to the buried ground ring via a connection to the post

This assembly eliminates the need for a solid copper busbar and down lead

The connection to the ground ring is concealed below grade

Accepts standard telecommunication grounding lugs (lugs not included)

Includes 14 Standard Spacers (TDSGAS) and 2 Pole Mount Spacers (TDSGAP)

Pole itself is not included in the assembly


SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Spacer Thickness	Length (L)	A	Thread Size (TS)
----------------	----------	--------	------------------	------------	---	------------------

TDSGAPA14	Copper, Stainless Steel 304 (EN 1.4301), Stainless Steel 18-8 (EN 1.4305), Nylon	Tinned	6.4mm	266mm	25.4 mm	3/8" UNC
-----------	--	--------	-------	-------	---------	----------

DIAGRAMS

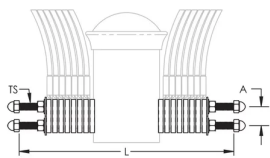

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ **WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE