


# Novastar Steel Door

## Power Utilities

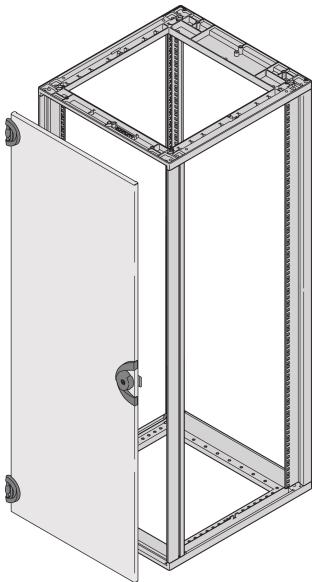

## CERTIFICATIONS



## FEATURES

St, 1.5 mm

Opening angle 180°, incl. grounding

Can be assembled at front and rear

Lock (2233x) with key

## SPECIFICATIONS

Table 1/2

| Catalog Number | Color      | Color Code | Height  | Product Type | Rack Height | Type       |
|----------------|------------|------------|---------|--------------|-------------|------------|
| 25230-020      | Black Grey | RAL 7021   | 323 mm  | Cabinet Door | 6 U         | Steel Door |
| 26230-020      | Light Grey | RAL 7035   | 323 mm  | Cabinet Door | 6 U         | Steel Door |
| 25230-021      | Black Grey | RAL 7021   | 422 mm  | Cabinet Door | 9 U         | Steel Door |
| 26230-021      | Light Grey | RAL 7035   | 422 mm  | Cabinet Door | 9 U         | Steel Door |
| 25230-022      | Black Grey | RAL 7021   | 555 mm  | Cabinet Door | 12 U        | Steel Door |
| 26230-022      | Light Grey | RAL 7035   | 555 mm  | Cabinet Door | 12 U        | Steel Door |
| 25230-023      | Black Grey | RAL 7021   | 733 mm  | Cabinet Door | 16 U        | Steel Door |
| 26230-023      | Light Grey | RAL 7035   | 733 mm  | Cabinet Door | 16 U        | Steel Door |
| 25230-024      | Black Grey | RAL 7021   | 911 mm  | Cabinet Door | 20 U        | Steel Door |
| 26230-024      | Light Grey | RAL 7035   | 911 mm  | Cabinet Door | 20 U        | Steel Door |
| 25230-025      | Black Grey | RAL 7021   | 1133 mm | Cabinet Door | 25 U        | Steel Door |
| 26230-025      | Light Grey | RAL 7035   | 1133 mm | Cabinet Door | 25 U        | Steel Door |
| 25230-030      | Black Grey | RAL 7021   | 736 mm  | Cabinet Door | 29 U        | Steel Door |
| 26230-030      | Light Grey | RAL 7035   | 736 mm  | Cabinet Door | 29 U        | Steel Door |
| 25230-026      | Black Grey | RAL 7021   | 1534 mm | Cabinet Door | 34 U        | Steel Door |
| 26230-026      | Light Grey | RAL 7035   | 1534 mm | Cabinet Door | 34 U        | Steel Door |
| 25230-027      | Black Grey | RAL 7021   | 1711 mm | Cabinet Door | 38 U        | Steel Door |
| 26230-027      | Light Grey | RAL 7035   | 1711 mm | Cabinet Door | 38 U        | Steel Door |

| CatalogNumber | Color      | Color Code | Height  | Product Type | Rack Height | Type       |
|---------------|------------|------------|---------|--------------|-------------|------------|
| 25230-028     | Black Grey | RAL 7021   | 1933 mm | Cabinet Door | 43 U        | Steel Door |
| 26230-028     | Light Grey | RAL 7035   | 1933 mm | Cabinet Door | 43 U        | Steel Door |
| 25230-029     | Black Grey | RAL 7021   | 2111 mm | Cabinet Door | 47 U        | Steel Door |
| 26230-029     | Light Grey | RAL 7035   | 2111 mm | Cabinet Door | 47 U        | Steel Door |

| Table 2/2      |        |
|----------------|--------|
| Catalog Number | Width  |
| 25230-020      | 553 mm |
| 26230-020      | 553 mm |
| 25230-021      | 553 mm |
| 26230-021      | 553 mm |
| 25230-022      | 553 mm |
| 26230-022      | 553 mm |
| 25230-023      | 553 mm |
| 26230-023      | 553 mm |
| 25230-024      | 553 mm |
| 26230-024      | 553 mm |
| 25230-025      | 553 mm |
| 26230-025      | 553 mm |
| 25230-030      | 553 mm |

| Catalog Number | Width  |
|----------------|--------|
| 26230-030      | 553 mm |
| 25230-026      | 553 mm |
| 26230-026      | 553 mm |
| 25230-027      | 553 mm |
| 26230-027      | 553 mm |
| 25230-028      | 553 mm |
| 26230-028      | 553 mm |
| 25230-029      | 553 mm |
| 26230-029      | 553 mm |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE