

Service Entrance Suppressor(F), 320 kA

Power Utilities



The nVent ERICO SES320 F Series of Surge Protective Devices (SPD) is an enhanced version of our nVent ERICO SES320B Series. The SES320 F Surge-Filter is robust and features a 320 kA per phase surge rating, increasing both survivability and overall life cycle. With the addition of a filter, bothersome high frequency transients on the power distribution system are attenuated, therefore protecting sensitive equipment. The F Series is a cUL 1449 Listed SPD for Type 2 locations. Typical applications for the nVent ERICO SES320 F Series service entrances, distribution, branch panels, MCC, lighting panels, HVAC, A/V systems, IT equipment, and more.

CERTIFICATIONS



FEATURES

Compact design can be directly mounted to panel or installed in a small space

Front-facing design eases installation and performance monitoring

320 kA 8/20 μ s maximum surge rating per phase

Up to 60 dB attenuation (10 kHz to 100 MHz)

Ground reference monitoring triggers an alarm when N-PE mode exceeds 20 volts

Optional Flush Mounting Plate

10-year limited warranty

SPECIFICATIONS


Catalog Number	SES320F480Y
Nominal System Voltage (Un)	277/480 V

Catalog Number	SES320F480Y
Max Continuous Operating Voltage (Uc)	350/700 V
Distribution System	3Ph Y 4W+G
Filtering	-40 dB @ 100 kHz
Frequency	0 – 600 Hz
Short Circuit Current Rating (SCCR)	200 kA
Voltage Protection Rating (VPR), L-L	2,000 V
Voltage Protection Rating (VPR), L-N	1,200 V
Nominal Discharge Current (In), Per Mode	20 kA 8/20 μ s
Protection Modes	All modes protected
Status Indication	1 green LED per line Dual color status LED, flashing red for faults Audible alarm
Remote Contact Switching Capacity	2.0 A @ 240 V
Remote Contacts	Yes
Lead Length	914 mm
Temperature	-40 to 85 °C
Enclosure Rating	NEMA®-4X UL® 50E Type 4
Unit Weight	0.626 kg
Certification Details	CSA C22.2 No. 269.2 UL® 1283 Edition 7 UL® 1449 Edition 5 Type 2, 20 kA Mode
Height (H)	175 mm
Width (W)	213 mm

ADDITIONAL PRODUCT DETAILS

Optional Flush Plate available: SES320FP

DIAGRAMS

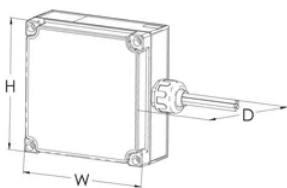

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE